

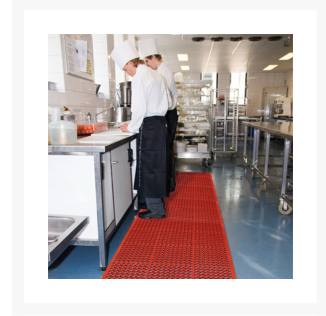
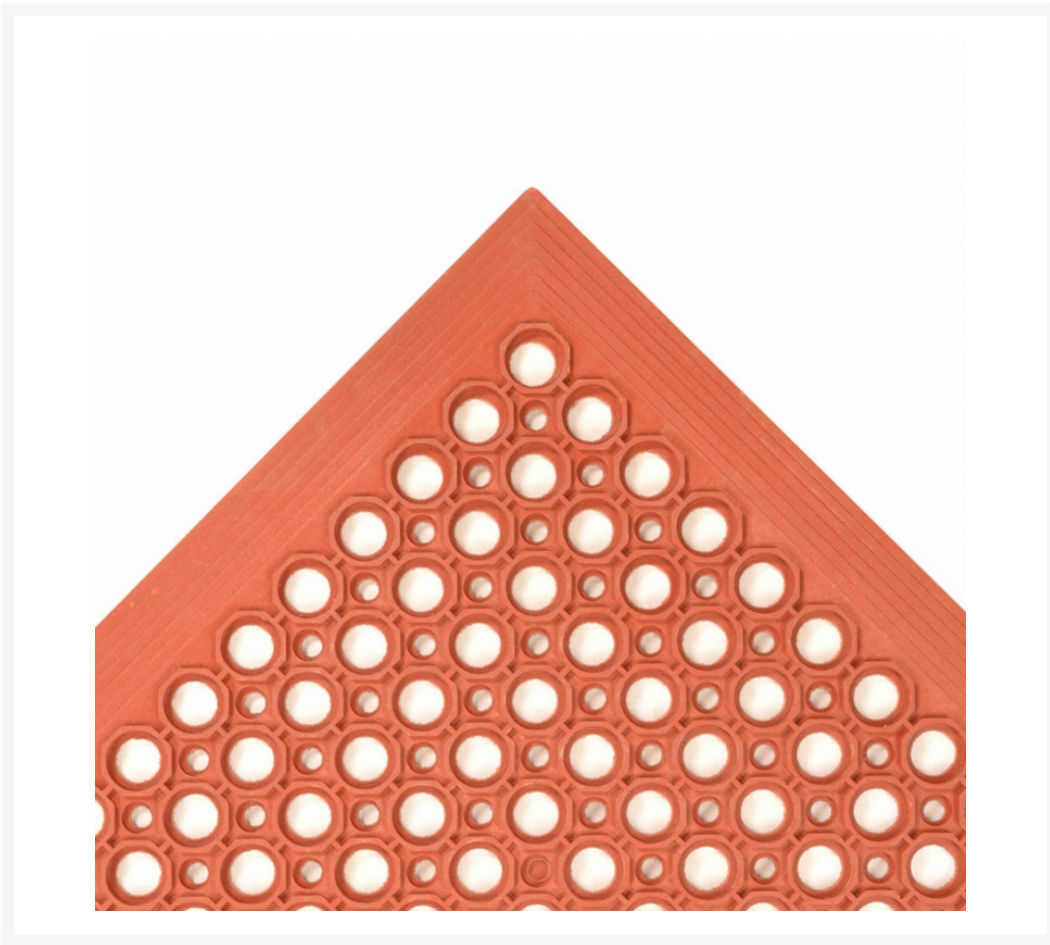


Durable Red Drainage Anti-Fatigue Mat Sanitop[®] 562RD

Product Images

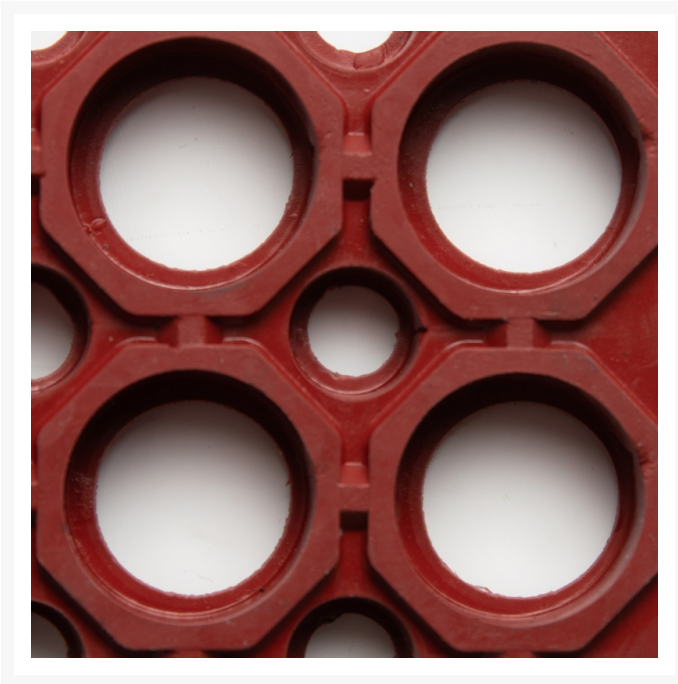

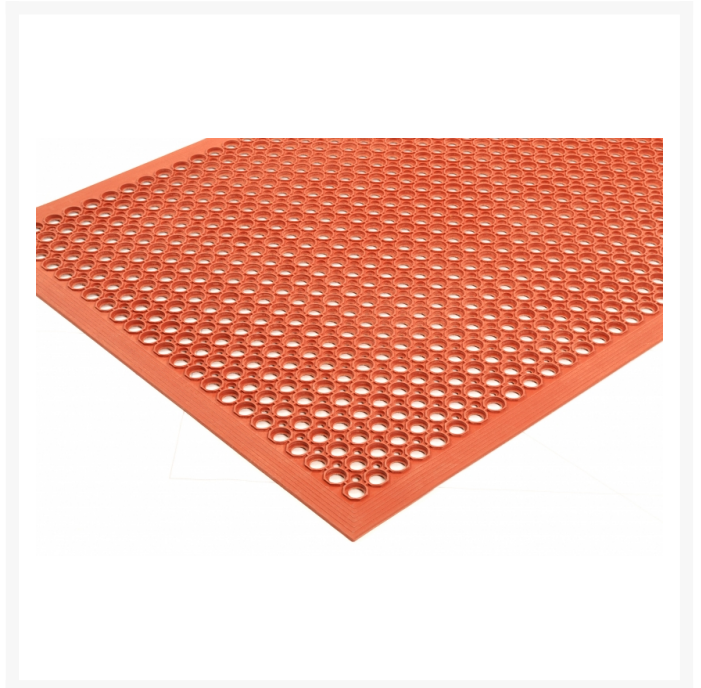

Short Description

- Durable rubber compound
- Molded alternating large/small hole drainage system keeps moisture and debris free from work area
- Raised pattern surround large holes to channel drainage and provide worker traction
- 100% Nitrile Grease Resistant
- Molded in beveled edges on all 4 sides

Description

Sanitop® is made from a durable rubber compound designed to withstand harsh chemicals while creating a slip resistant surface. Available in general purpose (black) and heavy-duty Nitrile (red) rubber compounds for varying degrees of grease and oil protection. A large and small hole drainage system channels liquid and debris away from the work area. Molded in beveled edges on all four sides eliminates trip hazards. Sanitop® offers a simple, economical solution for wet environments in many industrial or food service application.

Specifications

Model No	562RD
Available Colors	Red
Overall Thickness	1/2
Standard sizes	3'x 3'; 3'x 5'; 3'x 10'; 3'x 20'
Group	Ergonomic, Anti-fatigue & Safety Matting
Environment	Wet/Dry and Greasy Areas
Special Characteristics	Free of DOP, free of DMF, free of ozone depleting substances, free of silicone and free of heavy metals
Recommended Use	Food processing, professional kitchens, cooking lines, food preparation areas, bars and cleaning areas
Special Remarks	It's lightweight workstation design with molded beveled edges make it easier to pickup or move for cleaning
Surface	Large Drainage Holes
Edges	Molded beveled edges on all sides
Usage Intensity	Medium duty
Material Specifications	75% Nitrile rubber
Process	Compression Molding
Weight Lbs/sqft	1.4
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Anti-Fatigue Rating	Best
Slip Resistance Rating	Best
Wear Resistance Rating	Best
Grease Resistance Rating	Best

Dimensions:

3ft x 10ft

3ft x 20ft

3ft x 3ft

3ft x 5ft

Product Options