




---


# Ramps for De-Flex<sup>®</sup> Floor Mats 571

## Product Images

---

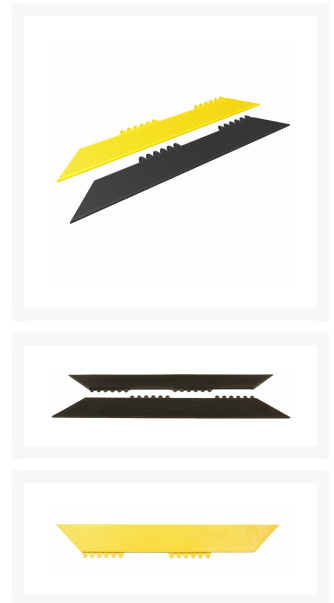

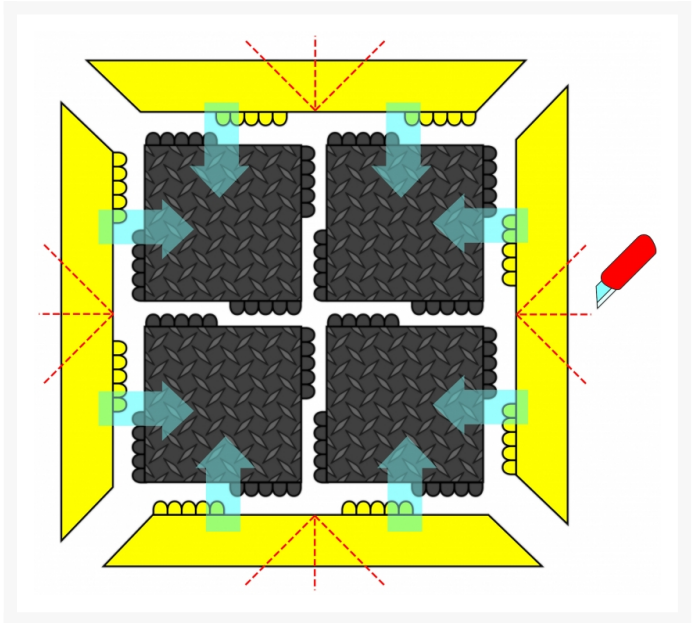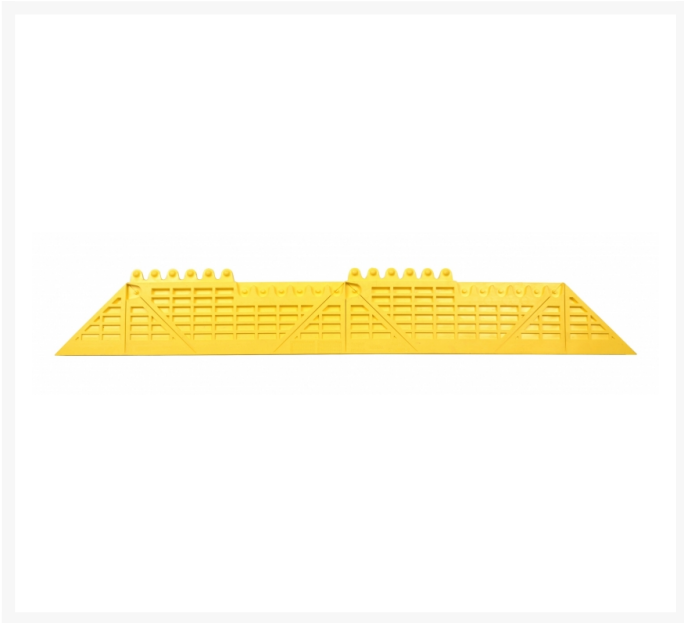

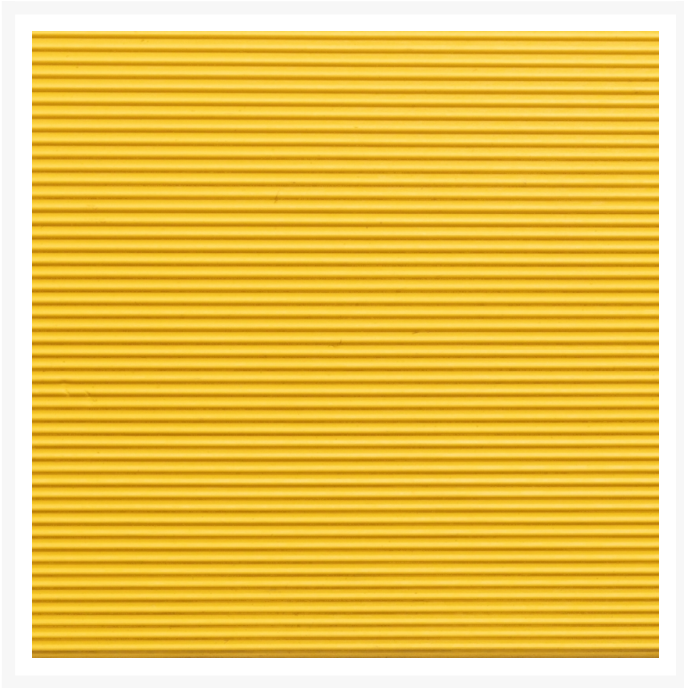

## Short Description

---

- Easy to snap together system for on-site custom work station platforms
- No male/female, ramp fits all sides of mat
- Nitrile provides highest level of resistance to chemicals, oils and greases
- Available as: 3 foot long ramps
- Compatible with any De-Flex® family mats

## Description

---

De-Flex® Ramps are designed for use with the De-Flex® family of floor mats and provides a 6" longer gradual beveled edge for greater ease onto or off of the work platform. Made from a 100% nitrile base rubber compound De-Flex® ramps provide the highest resistance to chemicals, cutting fluids, animal fats, oils and greases. Ramps fit either side of mat, eliminating the need for male/female ends and are beveled and molded with mitered corners and a protruding tab that locks together the two adjoining ramps for a secure, professional corner. Square edges can be achieved by trimming off the miter using the cut line on the bottom of the ramp.

## Specifications

---

Model No	571
Available Colors	Black; Yellow
Overall Thickness	3/4
Standard sizes	6"x 36"
Group	Ergonomic, Anti-fatigue & Safety Matting
Environment	Wet/Dry and Oily Areas
Special Characteristics	Free of DOP, free of DMF, free of ozone depleting substances, free of silicone and free of heavy metals   Resistant to most industrial oils
Recommended Use	For placement in manufacturing plants, assembly lines, picking, packing and logistics warehouses, individual work stations.
Special Remarks	All ramp lengths are beveled and molded with mitered corners and a protruding tab. The tab locks together the two adjoining ramps for a secure, professional corner.
Surface	Ribbed
Edges	Attachable beveled edges are available
Usage Intensity	Heavy duty
Material Specifications	100% Nitrile rubber
Process	Compression Molding
Weight Lbs/sqft	5
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Anti-Fatigue Rating	Best
Slip Resistance Rating	Best
Wear Resistance Rating	Best

## Product Options

---

Color:

Black

Yellow

Dimensions:

0.5ft x 3ft