
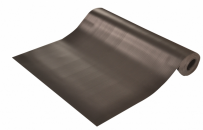


# Floor Protector Mat Vinyl V-Groove Corrugated 730

## Product Images

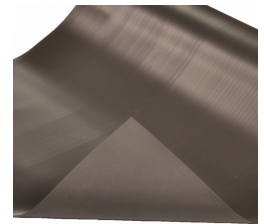

## Short Description

- Heavy-duty vinyl corrugated rib-tooth design improves traction and comfort
- Insulates floor and creates a silencing effect
- Oil, grease, and chemical resistant
- Motor Vehicle Safety Standard #302 (Flame Test) - Pass
- Low profile to eliminate trip hazards and allow for cart traffic
- Made of 100% recycled vinyl materials
- Utilizes a vinyl compound

## Description

---

V-Groove Corrugated Runner™ is made from a durable vinyl compound that features a rib-tooth design to improve traction. The vinyl runner protects floors, creates a barrier to cold flooring substrates, and has a silencing effect over noisy tile. The low profile matting allows for easy on/off cart traffic and can also be used as a liner for maintenance and tool carts.

## Specifications

---

Model No	730
Available Colors	Black
Overall Thickness	1/8
Roll Sizes	2'x 105'; 3'x 105'; 4'x 105'
Custom Lengths	2', 3' and 4' widths (up to 105' long)
Group	Ergonomic, Anti-fatigue & Safety Matting
Environment	Dry Areas
Recommended Use	For placement in manufacturing plants, assembly lines, picking, packing and logistics warehouses, individual work stations.
Special Remarks	Recommend for applications that require a little more traction. Can be used as a liner for maintenance and tool carts
Surface	Lengthwise Corrugated Rib Pattern
Edges	No borders
Usage Intensity	Medium duty
Material Specifications	PVC
Process	Calendering
Weight Lbs/sqft	0.7
Fire Rating US	Pass
Anti-Fatigue Rating	Good
Slip Resistance Rating	Better
Wear Resistance Rating	Better

## Prop 65

---

**⚠️WARNING:** This product can expose you to chemicals including di-2-ethylhexyl phthalate and/or diisononyl phthalate which is known to the State of California to cause cancer, birth defects or reproductive harm. For more information, visit [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

## Product Options

---

Dimensions:	2ft x 105ft
	2ft x Specify Length
	3ft x 105ft
	3ft x Specify Length
	4ft x 105ft
	4ft x Specify Length