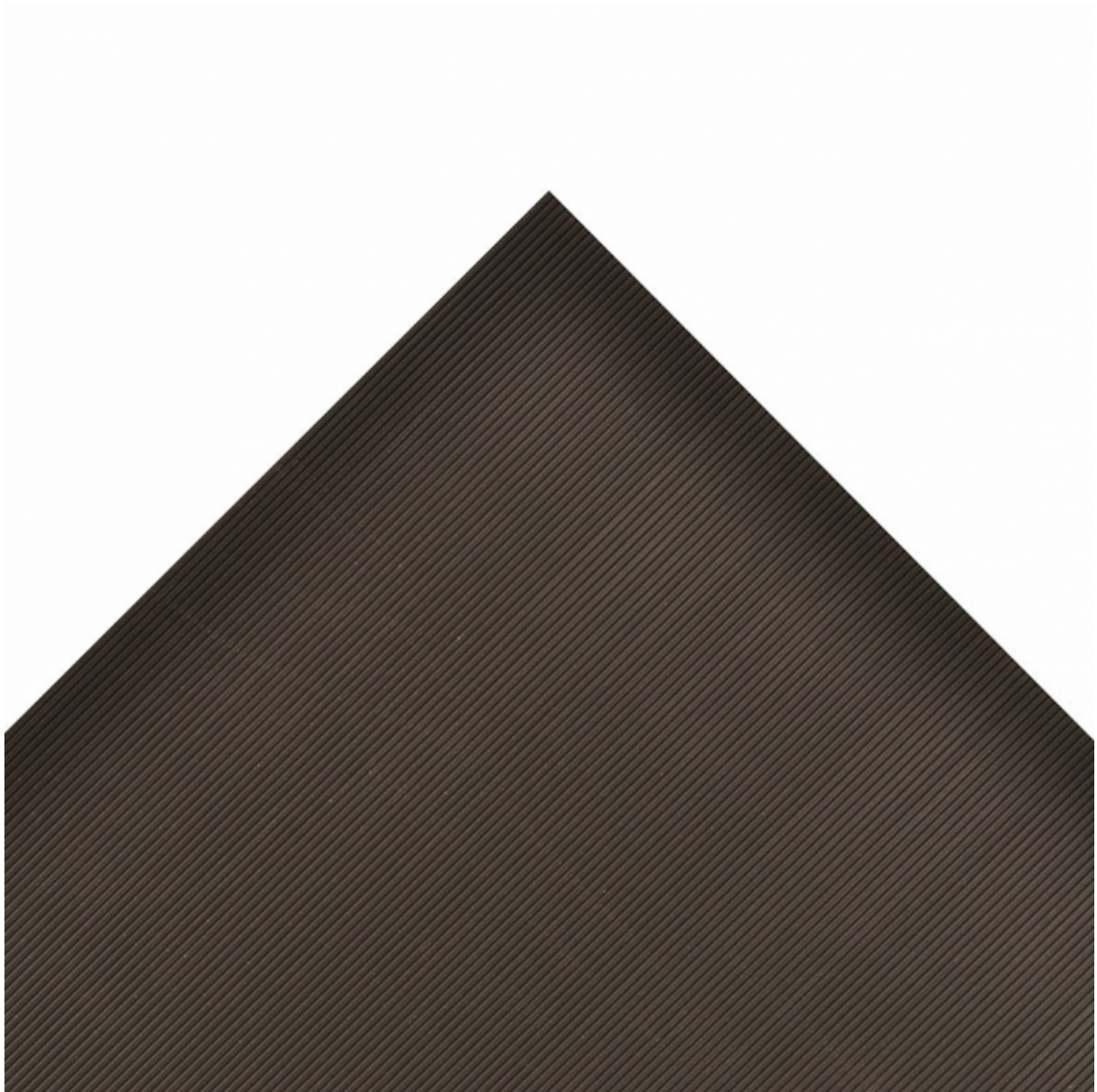

2' x Custom Length, Black, Vinyl V-Groove Corrugated Floor Protector Mat, 730

Product Images



Short Description

- Heavy-duty vinyl corrugated rib-tooth design improves traction and comfort
- Insulates floor and creates a silencing effect
- Oil, grease, and chemical resistant
- Motor Vehicle Safety Standard #302 (Flame Test) - Pass
- Low profile to eliminate trip hazards and allow for cart traffic

Description

V-Groove Corrugated Runner™ is made from a durable vinyl compound that features a rib-tooth design to improve traction. The vinyl runner protects floors, creates a barrier to cold flooring substrates, and has a silencing effect over noisy tile. The low profile matting allows for easy on/off cart traffic and can also be used as a liner for maintenance and tool carts.

Specifications

Model No	730C0024BL
Color	Black
Dimensions	2ft x Specify Length
Thickness	1/8in
UPC	662641648852
Brand	NoTrax
Roll Sizes	2'x105', 3'x105', 4'x105'
Custom Lengths	2', 3' and 4' widths (up to 105' long)
Group	Ergonomic, Anti-fatigue & Safety Matting
Environment	Dry Areas
Recommended Use	For placement in manufacturing plants, assembly lines, picking, packing and logistics warehouses, individual work stations.
Special Remarks	Recommend for applications that require a little more traction. Can be used as a liner for maintenance and tool carts
Edges	No borders
Usage Intensity	Medium duty
Material Specifications	PVC
Surface Detail	Lengthwise Corrugated Rib Pattern
Process	Calendering
Weight Lbs/sqft	0.7
Thickness Inch	1/8in
Fire Rating US	Pass
Anti-Fatigue Rating	Good
Slip Resistance Rating	Better
Wear Resistance Rating	Better

Prop 65

⚠️WARNING: This product can expose you to chemicals including di-2-ethylhexyl phthalate and/or diisononyl phthalate which is known to the State of California to cause cancer, birth defects or reproductive harm. For more information, visit www.P65Warnings.ca.gov.