
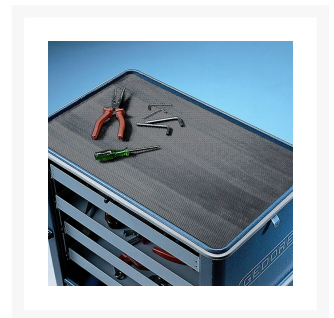


# Floor Protector Rubber Mat, V-Groove Corrugated Runner<sup>™</sup>, 750

## Product Images

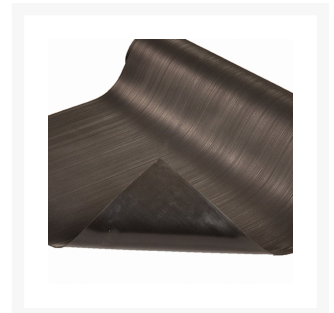

## Short Description

- Heavy-duty rubber corrugated rib-tooth design improves traction and comfort
- Insulates floor and creates a silencing effect
- Oil, grease, and chemical resistant
- Provides barrier to cold floors and floor protection
- Low profile to eliminate trip hazards and allow for cart traffic
- Performs at low temperatures and is suitable for indoor and outdoor use
- Motor Vehicle Safety Standard #302 (Flame Test) - Pass

## Description

---

V-Groove Corrugated Runner™ is made from a long-lasting rubber compound that features a rib-tooth design and provides sure footing and floor protection. This corrugated-rubber-mat also creates a barrier to cold flooring substrates, and has a silencing effect over noisy tile. The low profile corrugated rubber mat allows for easy on/off cart traffic and can also be used as a liner for maintenance and tool carts.

## Specifications

---

Model No	750
Available Colors	Black
Overall Thickness	1/8
Roll Sizes	2'x 75'; 2'x 150'; 3'x 75'; 3'x 150'; 4'x 75'; 4'x 150'; 6'x 75'
Custom Lengths	2', 3', 4' and 6' widths (up to 150' long)
Group	Ergonomic, Anti-fatigue & Safety Matting
Environment	Dry Areas
Special Characteristics	Free of DOP, free of DMF, free of ozone depleting substances, free of silicone and free of heavy metals
Recommended Use	For placement in manufacturing plants, assembly lines, picking, packing and logistics warehouses, individual work stations.
Special Remarks	Recommend for applications that require a little more traction. Can be used as a liner for maintenance and tool carts
Surface	Lengthwise Corrugated Rib Pattern
Edges	No borders
Usage Intensity	Light duty
Material Specifications	SBR Rubber
Process	Calendering
Weight Lbs/sqft	0.8
Temperature Range	- 40 ° C up to + 120 ° C
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Anti-Fatigue Rating	Good
Slip Resistance Rating	Better
Wear Resistance Rating	Best

## Prop 65

---

**⚠️WARNING:** This product can expose you to chemicals including di-2-ethylhexyl phthalate and/or diisononyl phthalate which is known to the State of California to cause cancer, birth defects or reproductive harm. For more information, visit [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

## Product Options

---

Dimensions:	2ft x 150ft
	2ft x 75ft
	2ft x Specify Length
	3ft x 150ft
	3ft x 75ft
	3ft x Specify Length
	4ft x 150ft
	4ft x 75ft
	4ft x Specify Length
	6ft x 75ft
	6ft x Specify Length