
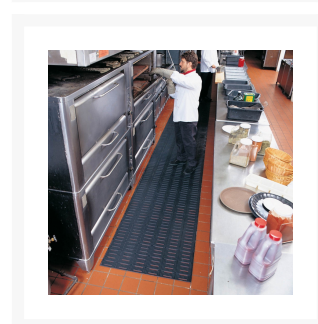


Floor Protector Mat Niru® Versa Runner™ 755

Product Images

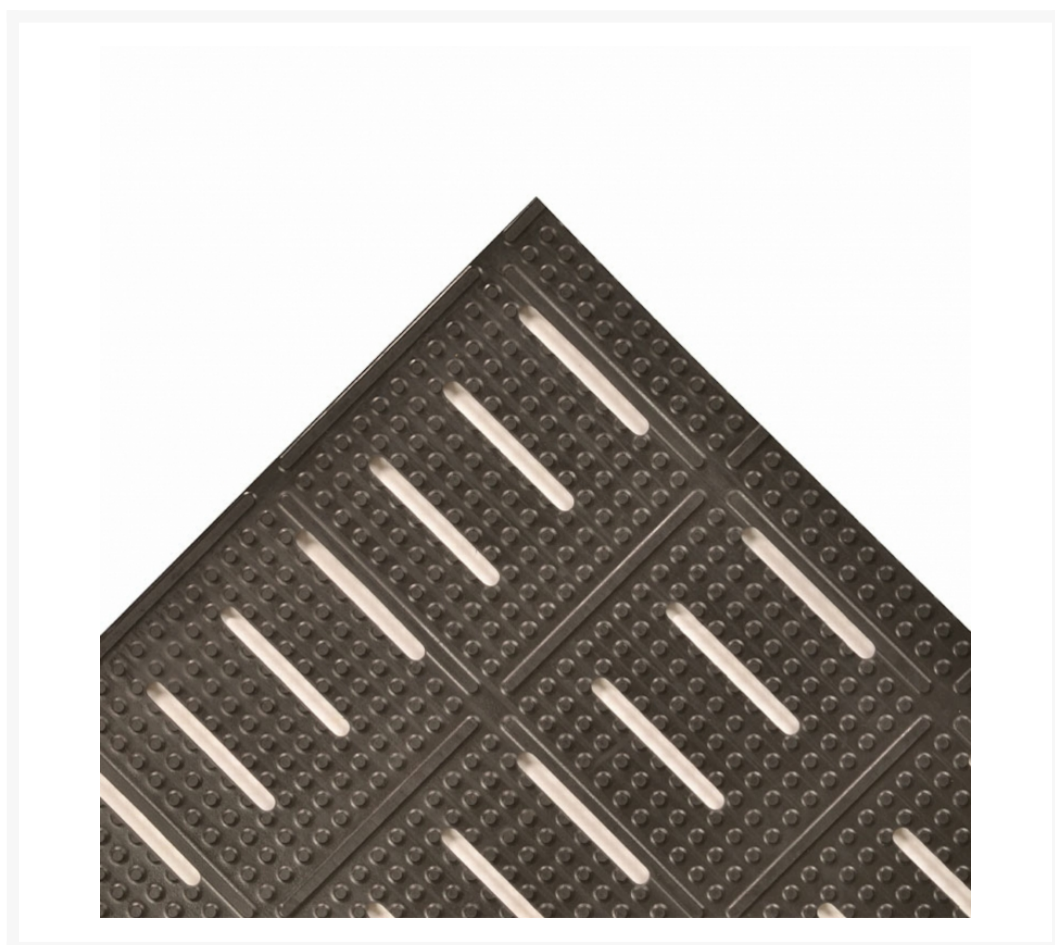

Short Description

- Made from a durable grease-proof 100% nitrile rubber compound
- Slotted perforations for drainage
- Ribbed underside adds anti-fatigue value and channels liquid away from the mat
- Low profile allows for easy on/off cart traffic

Description

Niru® Versa Runner™ is made from a 100% Nitrile rubber compound designed to withstand harsh chemicals, greases, oils, and animal fats while creating a slip resistant work surface. Slotted perforations allow for drainage and a scraper-rib design runs side-to-side on the mat for added traction. The ribbed underside enhances the anti-fatigue value of the mat and also helps to channel liquid away from the work area. Its low profile allows for use in areas with high cart traffic. Niru® Versa Runner™ is perfect for wet or dry applications that require traction and drainage in a continuous mat.

Specifications

Model No	755
Available Colors	Black
Overall Thickness	3/8
Roll Sizes	2'x 60'; 3'x 60'; 4'x 60'
Custom Lengths	2', 3' and 4' widths (up to 60' long)
Standard sizes	2'x 3'; 3'x 4'
Group	Ergonomic, Anti-fatigue & Safety Matting
Environment	Wet/Dry and Oily Areas
Recommended Use	Restaurant kitchens, food prep, food processing environments
Special Remarks	Provides traction, resistance to harsh chemicals, oils, and greases, and basic anti-fatigue support in a longer run. Reversible design further extends the service life of the mat. Drainage hole size: 3-3/8" x 3/8"
Surface	Industrial Bubble Pattern
Material Specifications	NBR (nitrile) rubber
Process	Molding
Weight Lbs/sqft	1.5
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Anti-Fatigue Rating	Good
Slip Resistance Rating	Best
Wear Resistance Rating	Better

Prop 65

⚠️WARNING: This product can expose you to chemicals including diisodecyl phthalate which is known to the State of California to cause birth defects or reproductive harm. For more information, visit www.P65Warnings.ca.gov.

Product Options

Dimensions:	2ft x 3ft
	2ft x 60ft
	2ft x Specify Length
	3ft x 4ft
	3ft x 60ft
	3ft x Specify Length
	4ft x 60ft
	4ft x Specify Length