




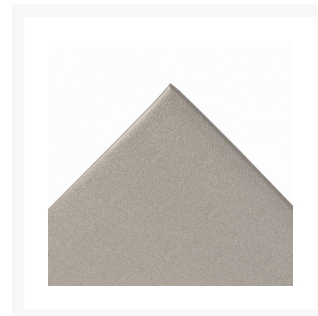


Anti-Fatigue Mat Cushion-Stat™ W/ Dyna-Shield® 825

Product Images

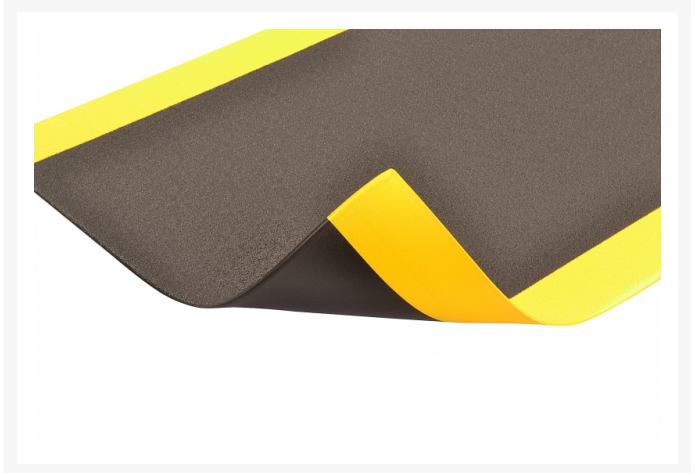

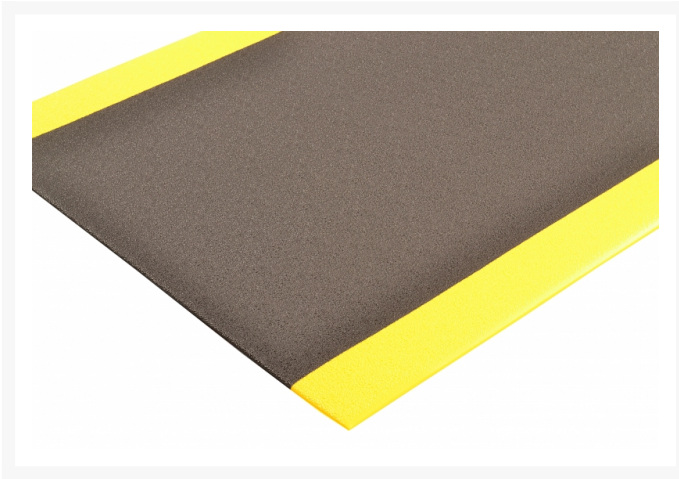

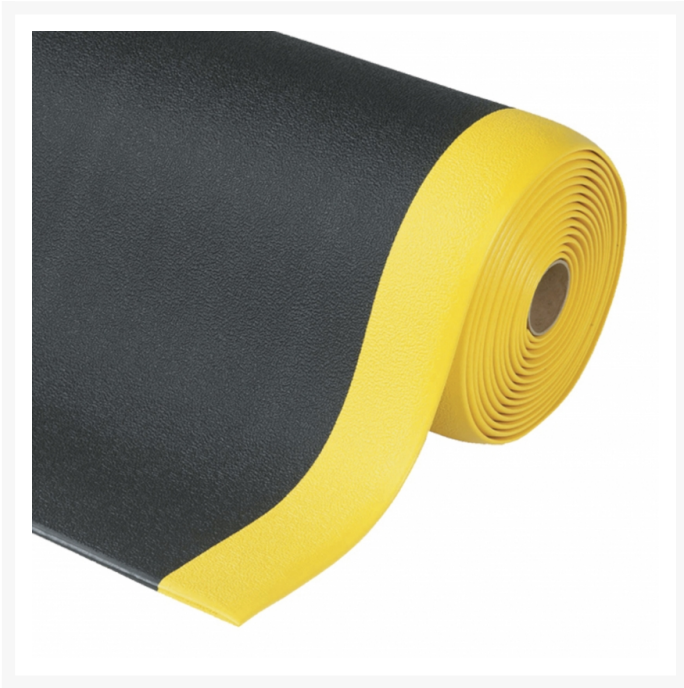

Short Description

- Static dissipative PVC sponge. Absorbs static electricity keeping sensitive electronic circuitry safe
- Pebble textured embossed mat provides added cushioning and relieves leg and back discomfort
- Exclusive Dyna-Shield® top surface manufactured directly into the mat for long lasting wear
- Meets or exceeds requirements of ANSI/ESD S20.20 and per ANSI/ESD STM7.1 and ESD TR53
- Resistance Point to Point (Rtt): 10^9 ohms
Resistance Point to Ground (Rtg): 10^9 ohms
- Beveled edges on all 4 sides
- 051 Grounding cord available, not required

Description

Cushion Stat™ w/ Dyna-Shield® is a dissipative/anti-static mat that is specially formulated to absorb static electricity keeping sensitive electronic circuitry safe from damage. The anti-fatigue properties are designed to provide traction with its non-directional pebble embossed top surface that allows for sure footing and is easy to sweep clean. The Notrax® exclusive Dyna-Shield® PVC foam is manufactured with a tough protective top layer that provides long lasting wear and outperforms the competition in tear resistance and tensile strength. Designed for use in medium duty dry work areas.

Specifications

Model No	825
Available Colors	Black; Black/Yellow; Gray
Overall Thickness	3/8
Roll Sizes	3'x 60'; 4'x 60'
Custom Lengths	3' and 4' widths (up to 60' long)
Standard sizes	2'x 3'; 3'x 5'; 3'x 10'
Group	Ergonomic, Anti-fatigue & Safety Matting
Environment	Dry Areas
Special Characteristics	Free of DOP, free of DMF, free of ozone depleting substances, free of silicone and free of heavy metals
Recommended Use	For placement in ESD assembly lines, picking, packing and logistics warehouses, individual work stations.
Special Remarks	With Dyna-Shield® - The only mid-priced/high performance anti-fatigue sponge mat available with durability approaching that of competitive "laminated" mats. Extends service life by 50%.
Surface	Structured Pebble Pattern
Edges	Beveled edges on all sides
Usage Intensity	Medium duty
Custom Description	Available in stock and rolls sizes and in custom lengths. Available colors in gray, black/yellow and black.
Cleaning Remark	Sweep regularly or dry mop the surface and the back of the mat. The surface can be damp-mopped with a mild soap/detergent. Use ESD mat cleaner.
Process	Foaming
Weight Lbs/sqft	0.64
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Anti-Fatigue Rating	Better
Slip Resistance Rating	Better

Wear Resistance Rating

Better

Product Options

Color:

Black

Black/Yellow

Gray

Dimensions:

2ft x 3ft

3ft x 10ft

3ft x 5ft

3ft x 60ft

3ft x Specify Length

4ft x 60ft

4ft x Specify Length