


---

## 2.5' x Custom Length, Blue, Anti-Stat P.O.P.™ ESD Anti Static Mat, 827

### Product Images

---

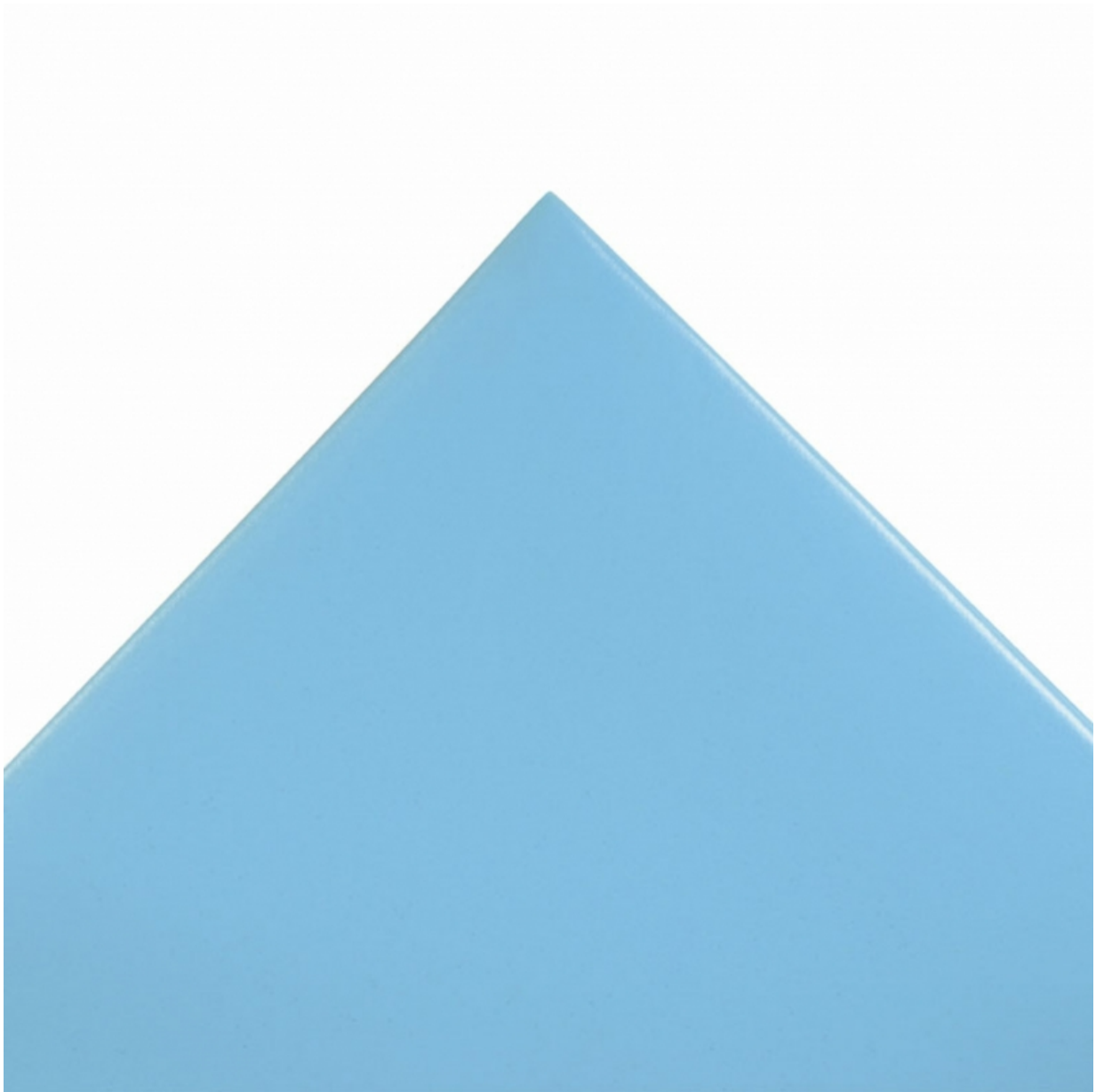

## Short Description

---

- Static dissipative vinyl work surface that dissipates static from conductive items placed on it
- Protects table and keeps sensitive components safe from damaging static shocks
- Single layer, smooth top surface that is abrasion resistant and easy to wipe clean
- Meets EOS/ESD-S4, measured resistance for work surfaces RG  $10^7 \Omega$  and RP  $10^8 \Omega$
- Electrostatic charge (walking test), meets ISO6356 and EN1815

## Description

---

Specialized line of ESD Anti-Stat P.O.P.™ to ensure a static free workplace and protect employees and sensitive electrical equipment. Use Anti-Stat P.O.P.™ to connect table work surface, employees and conductive material to a common grounding point. This creates a balance between all items and personnel to ensure static electricity will flow to ground in a controlled manner. For use in ESD working zones to protect electrostatic sensitive components.

Static dissipative vinyl work surface that static load from conductive items placed on it. Protects table and keeps sensitive components safe from damaging static shocks. Smooth top surface that is abrasion resistant and easy to wipe clean. Optional grounding cord. Microcellular vinyl foam treated with dissipative static properties. Meets EOS/ESD-S4, measured resistance Rg  $10^7 \Omega$  and Rp  $10^8 \Omega$ . Electrostatic charge (walking test), meets ISO6356 and EN1815.

## Specifications

|                         |                                                                                                         |
|-------------------------|---------------------------------------------------------------------------------------------------------|
| Model No                | 827C0030BU                                                                                              |
| Color                   | Blue                                                                                                    |
| Dimensions              | 2.5ft x Specify Length                                                                                  |
| Thickness               | 1/4in                                                                                                   |
| UPC                     | 662641722620                                                                                            |
| Brand                   | NoTrax                                                                                                  |
| Available Colors        | Blue                                                                                                    |
| Custom Lengths          | 2', 30" and 3' widths (up to 60' long)                                                                  |
| Standard sizes          | 30"x40', 3'x40'                                                                                         |
| Group                   | Ergonomic, Anti-fatigue & Safety Matting                                                                |
| Environment             | Dry Areas                                                                                               |
| Special Characteristics | Free of DOP, free of DMF, free of ozone depleting substances, free of silicone and free of heavy metals |
| Recommended Use         | For use in ESD working zones to protect electrostatic sensitive components                              |
| Special Remarks         | Anti-Static table top single layer work surface                                                         |
| Edges                   | Beveled edges on all sides                                                                              |
| Usage Intensity         | Medium duty                                                                                             |
| Custom Description      | Available in rolls sizes and in custom lengths. Available in blue.                                      |
| Material Specifications | Closed Cell Polyvinylchloride                                                                           |
| Surface Detail          | Smooth Even Surface                                                                                     |
| Process                 | Foaming                                                                                                 |
| Weight Lbs/sqft         | 0.63                                                                                                    |
| Thickness Inch          | 1/4in                                                                                                   |
| Fire Rating US          | Pass                                                                                                    |
| REACH Compliant         | Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).                 |

|                        |        |
|------------------------|--------|
| Anti-Fatigue Rating    | Good   |
| Slip Resistance Rating | Better |
| Wear Resistance Rating | Better |