 



2' x Custom Length, Black-Yellow, Cushion Trax® Ultra™ Anti Fatigue Mat, 975

Product Images



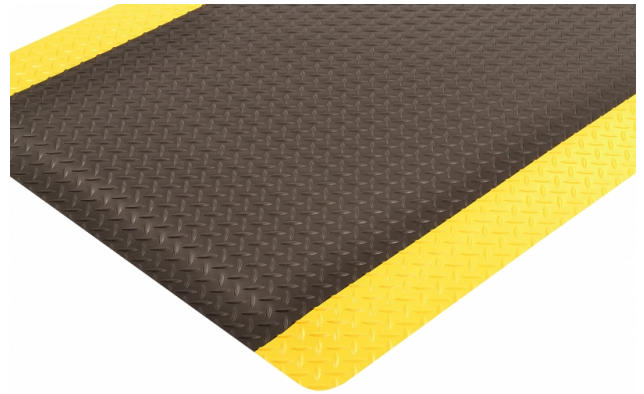

Short Description

- Long-lasting vinyl top surface made from 100% recycled materials is combined with a dense closed cell PVC foam base
- Diamond-plate surface texture provides added traction
- UniFusion™ bond guaranteed for the life of the mat
- Redstop™ non-slip backing to reduce mat slippage
- Beveled edges on all 4 sides

Description

Cushion Trax® Ultra™ is the ultimate high performance anti-fatigue floor mat. Engineered to meet the toughest requirements of today's industrial applications and is particularly suited for multi-shift operations in dry work areas where the worker is standing for prolonged periods of time; workstations, assembly lines. The heavy-duty vinyl diamond-plate design provides non-directional traction, and is easy to clean. The top surface is combined with a dense closed cell foam base utilizing NoTrax® exclusive UniFusion™ technology. This virtually eliminates the possibility of de-lamination. NoTrax® laminate floor mats that come with RedStop™, a uniquely engineered non-slip backing technology, eliminates the slipping and sliding of floor mats on smooth surface flooring such as tile, wood, marble, and treated concrete. The sloped beveled edges reduce tripping hazards and allow easy access on and off the mat.

Model No	975C0024YB
Color	Black/Yellow
Dimensions	2ft x Specify Length
Thickness	3/4in
UPC	662641821460
Brand	NoTrax
Available Colors	Black/Yellow
Roll Sizes	2'x75', 3'x75', 4'x75', 5'x75'
Custom Lengths	2', 3', 4' and 5' widths (up to 75' long)
Standard sizes	2'x3', 3'x5', 3'x12'
Group	Ergonomic, Anti-fatigue & Safety Matting
Environment	Dry Areas
Special Characteristics	Coefficient of friction NSF1 certified Free of DOP, free of DMF, free of ozone depleting substances, free of silicone and free of heavy metals
Recommended Use	In manufacturing plants, assembly lines, picking, packing and logistics warehouses, individual workstations. Also suitable for commercial environments including hotels, reception desks, shop counters, department stores, banks, restaurants, etc.
Special Remarks	Diamond plate surface texture provides non-directional slip resistance that's easy to sweep clean. 3/4" thick version for varying levels of comfort.
Edges	Beveled edges on all sides
Usage Intensity	Heavy duty
Material Specifications	PVC on microcellular vinyl base
Surface Detail	Industrial Diamond Plate
Backing	Closed Cell Polyvinylchloride with RedStop™ slip-resistant backing
Process	Lamination
Weight Lbs/sqft	1.4

Specifications

Thickness Inch	3/4in
Fire Rating US	Pass
REACH Compliant	Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals).
Anti-Fatigue Rating	Superior
Slip Resistance Rating	Superior
Wear Resistance Rating	Superior

Prop 65

⚠️WARNING: This product can expose you to chemicals including di-2-ethylhexyl phthalate and/or diisononyl phthalate which is known to the State of California to cause cancer, birth defects or reproductive harm. For more information, visit www.P65Warnings.ca.gov.