
 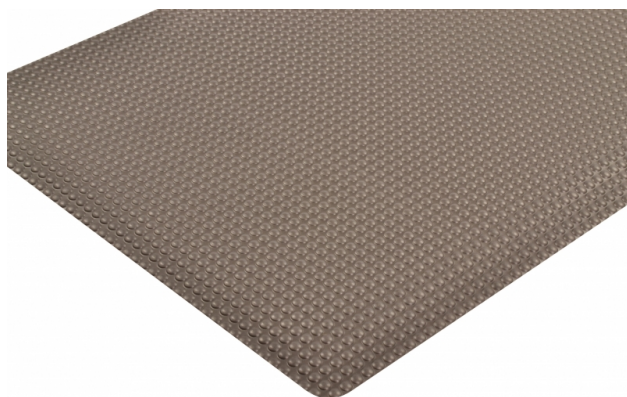


# 3' x Custom Length, Black, Bubble Trax® Grande™ Anti Fatigue Mat, 982

## Product Images



## Short Description

---

- Heavy-duty vinyl bubble top surface combined with a dense closed cell PVC foam base provides added cushioning comfort
- UniFusion™ bond guaranteed for the life of the mat
- Redstop™ non-slip backing to reduce mat slippage
- Beveled edges on all 4 sides
- Certified by the NFSI (National Floor Safety Institute)

## Description

---

Bubble Trax® Grande™ is an unique high performance anti-fatigue floor mat with a bubble top surface design and is a full ONE-INCH thick providing the ultimate in ergonomic comfort and durability. Bubble Trax® Grande™ combines a heavy-duty vinyl top surface with a dense sponge backing utilizing NoTrax® exclusive UniFusion™ technology. This virtually eliminates the possibility of de-lamination. NoTrax® laminate floor mats that come with RedStop™, a uniquely engineered non-slip backing technology, eliminates the slipping and sliding of floor mats on smooth surface flooring such as tile, wood, marble, and treated concrete. The sloped beveled edges reduce tripping hazards and allow easy access on and off the mat. Extremely well suited for multi-shift operations in dry work area where the worker is standing for prolonged periods of time; workstations, assembly lines.

# Specifications

|                         |                                                                                                                                                                          |
|-------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Model No                | 982C0036BL                                                                                                                                                               |
| Color                   | Black                                                                                                                                                                    |
| Dimensions              | 3ft x Specify Length                                                                                                                                                     |
| Thickness               | 1in                                                                                                                                                                      |
| UPC                     | 662641843196                                                                                                                                                             |
| Brand                   | NoTrax                                                                                                                                                                   |
| Roll Sizes              | 2'x72', 3'x72', 4'x72', 5'x72' * Gray not available in 4'x72' and 5'x72' widths                                                                                          |
| Custom Lengths          | 2', 3', 4' and 5' widths (up to 72' long) * Gray not available in 4' and 5' widths                                                                                       |
| Standard sizes          | 2'x3', 3'x5'                                                                                                                                                             |
| Group                   | Ergonomic, Anti-fatigue & Safety Matting                                                                                                                                 |
| Environment             | Dry Areas                                                                                                                                                                |
| Special Characteristics | Coefficient of friction NSF1 certified   Free of DOP, free of DMF, free of ozone depleting substances, free of silicone and free of heavy metals                         |
| Recommended Use         | For placement in manufacturing plants, production lines, assembly lines, CNC machines, metal working for individual workstations and custom work platforms               |
| Special Remarks         | Bubble-top design for greater comfort and ergonomic support. Ideal for multi-shift environments. Full 1" thick version for applications that require additional comfort. |
| Edges                   | Beveled edges on all sides                                                                                                                                               |
| Usage Intensity         | Heavy duty                                                                                                                                                               |
| Material Specifications | PVC on microcellular vinyl base                                                                                                                                          |
| Surface Detail          | Industrial Bubble Pattern                                                                                                                                                |
| Backing                 | Closed Cell Polyvinylchloride with RedStop™ slip-resistant backing                                                                                                       |
| Process                 | Lamination                                                                                                                                                               |
| Weight Lbs/sqft         | 1.7                                                                                                                                                                      |
| Thickness Inch          | 1in                                                                                                                                                                      |

|                        |                                                                                         |
|------------------------|-----------------------------------------------------------------------------------------|
| Fire Rating US         | Pass                                                                                    |
| REACH Compliant        | Reach compliant (Registration, Evaluation, Authorization and Restriction of Chemicals). |
| Anti-Fatigue Rating    | Superior                                                                                |
| Slip Resistance Rating | Superior                                                                                |
| Wear Resistance Rating | Superior                                                                                |

## Prop 65

---

**⚠️WARNING:** This product can expose you to chemicals including di-2-ethylhexyl phthalate and/or diisononyl phthalate which is known to the State of California to cause cancer, birth defects or reproductive harm. For more information, visit [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).