


# 2' x Custom Length, Black-Yellow, Ergo Trax® Grande™ Anti Fatigue Mat, 985

## Product Images

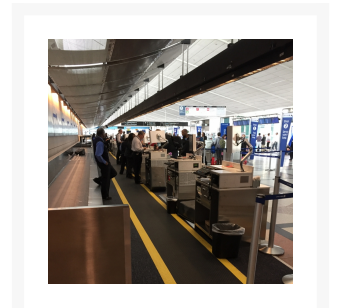

## Short Description

- Heavy duty vinyl top surface combined with Niru® rubber base provides superior durability and traction
- Niru® rubber foam base provides high friction to reduction in mat movement
- Vinyl top surface is made of 100% recycled materials
- UniFusion™ bond guaranteed for the life of the mat
- Beveled edges on all 4 sides

## Description

---

Ergo Trax® Grande™ is a thicker, heavier and stronger anti-fatigue floor mat. Engineered to meet the toughest requirements of today's industrial applications and is particularly suited for multi-shift operations in dry work areas. At a full ONE-INCH thick, it is the ultimate anti-fatigue product maximizing worker productivity and comfort. The durable vinyl diamond-plate top surface design provides non-directional traction and is easy to clean. The top surface is combined with a Niru® rubber sponge base utilizing NoTrax® exclusive UniFusion™ technology that virtually eliminates the possibility of de-lamination. The sloped beveled edges reduce tripping hazards and allow easy access on and off the mat.

## Specifications

|                         |                                                                                                                             |
|-------------------------|-----------------------------------------------------------------------------------------------------------------------------|
| Model No                | 985C0024YB                                                                                                                  |
| Color                   | Black/Yellow                                                                                                                |
| Dimensions              | 2ft x Specify Length                                                                                                        |
| Thickness               | 1in                                                                                                                         |
| UPC                     | 662641900073                                                                                                                |
| Brand                   | NoTrax                                                                                                                      |
| Roll Sizes              | 2'x75', 3'x75', 4'x75'                                                                                                      |
| Custom Lengths          | 2', 3' and 4' widths (up to 75' long)                                                                                       |
| Standard sizes          | 2'x3', 3'x5', 3'x12'                                                                                                        |
| Group                   | Ergonomic, Anti-fatigue & Safety Matting                                                                                    |
| Environment             | Dry Areas                                                                                                                   |
| Special Characteristics | Coefficient of friction NSF1 certified                                                                                      |
| Recommended Use         | For placement in manufacturing plants, assembly lines, picking, packing and logistics warehouses, individual work stations. |
| Special Remarks         | Vinyl top surface makes it easy to sweep or mop clean. Ideal for multi-shift environments                                   |
| Edges                   | Beveled edges on all sides                                                                                                  |
| Usage Intensity         | Heavy duty                                                                                                                  |
| Installation            | v                                                                                                                           |
| Material Specifications | PVC on microcellular vinyl base                                                                                             |
| Surface Detail          | Industrial Diamond Plate                                                                                                    |
| Backing                 | Closed Cell Polyvinylchloride                                                                                               |
| Process                 | Lamination                                                                                                                  |
| Weight Lbs/sqft         | 1.3                                                                                                                         |
| Thickness Inch          | 1in                                                                                                                         |
| Fire Rating US          | Pass                                                                                                                        |

|                        |          |
|------------------------|----------|
| Anti-Fatigue Rating    | Superior |
| Slip Resistance Rating | Superior |
| Wear Resistance Rating | Superior |

## Prop 65

---

**⚠️WARNING:** This product can expose you to chemicals including di-2-ethylhexyl phthalate and/or diisononyl phthalate which is known to the State of California to cause cancer, birth defects or reproductive harm. For more information, visit [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).