


Interchange Element Data Sheet

Data sheet created using the Parker Par Fit Toolkit software.

Creation Date:	02/10/2018
Datasheet No:	
Parker Part No:	270-Z-222A
OEM:	Parker Original
OEM Part No:	200 series Arlon

Product Dimensions

A (mm)	73.7	(inch)	2.90
B (mm)	33.0	(inch)	1.30
D (mm)	33.0	(inch)	1.30
E (mm)	237.3	(inch)	9.34

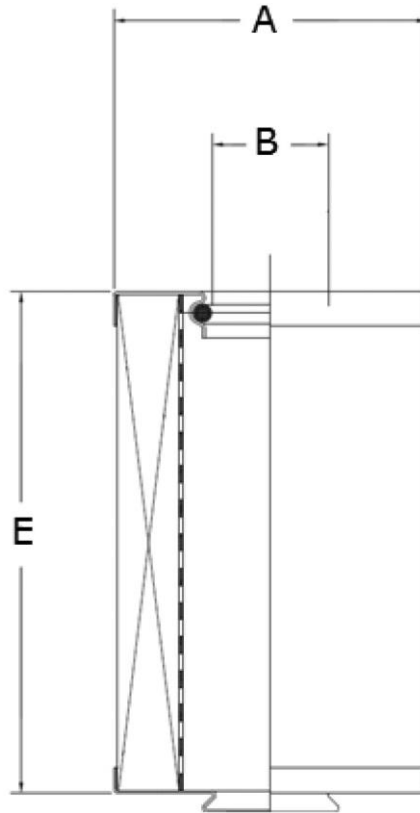

Construction Materials

Seal(s):	NBR: Nitrile
Top Endcap:	Steel zinc plated
Bottom Endcap:	Steel zinc plated
Inner Support Cylinder:	Steel nickel plated
Filter Media:	Multilayer fiberglass with epoxy coated mesh on both sides

Calculated Performance Criteria

Differential Pressure (Δp):	bar @ l/min
Tested to ISO3968 @ 32 cSt	psi @ gpm
Efficiency	>Beta 200 @ 9 microns & greater >Beta 1000 @ 12 microns & greater
Minimum Collapse Pressure:	>20 bar
Tested to ISO2941	>290 psi
Dirt Holding Capacity acc. to ISO16889	