


Interchange Element Data Sheet

Data sheet created using the Parker Par Fit Toolkit software.

Creation Date:	05/09/2018
Datasheet No:	
Parker Part No:	927694Q
OEM:	Parker Original
OEM Part No:	15P-2

Product Dimensions

A (mm)	45.0	(inch)	1.77
B (mm)	25.4	(inch)	1.00
D (mm)	45.0	(inch)	1.77
E (mm)	208.3	(inch)	8.20

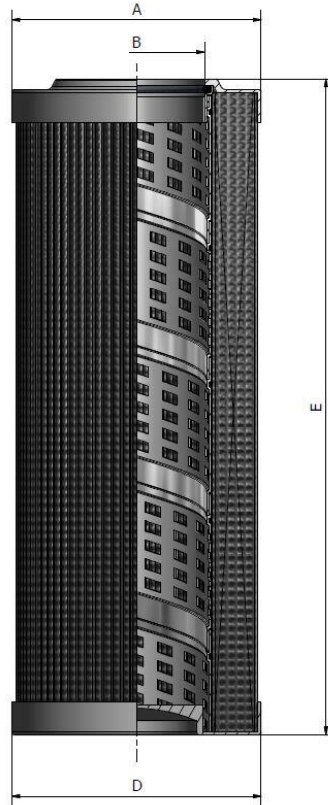

Construction Materials

Seal(s):	FKM: Fluorocarbon
Top Endcap:	Steel zinc plated
Bottom Endcap:	Steel zinc plated
Inner Support Cylinder:	Steel tin plated (wrapped)
Filter Media:	Multilayer fiberglass with coated mesh on the inflow side and stainless steel mesh on the outlet side

Calculated Performance Criteria

Differential Pressure (Δp):	0.03 bar @ l/min
Tested to ISO3968 @ 32 cSt	0.43 psi @ gpm
Efficiency	>Beta 200 @ 16 microns & greater >Beta 1000 @ 20 microns & greater
Minimum Collapse Pressure:	>207 bar
Tested to ISO2941	>3000 psi
Dirt Holding Capacity acc. to ISO16889	