


Interchange Element Data Sheet

Data sheet created using the Parker Par Fit Toolkit software.

Creation Date:	05/09/2018
Datasheet No:	
Parker Part No:	930197Q
OEM:	Pall
OEM Part No:	HC9800FKN4Z

Product Dimensions

A (mm)	50.3	(inch)	1.98
B (mm)	24.9	(inch)	0.98
D (mm)	50.3	(inch)	1.98
E (mm)	115.8	(inch)	4.56

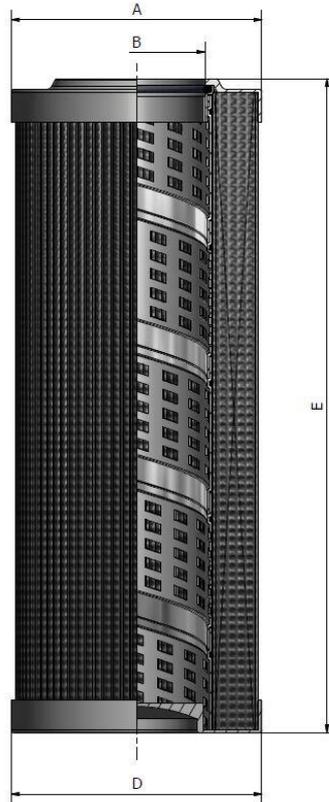

Construction Materials

Seal(s):	FKM: Fluorocarbon
Top Endcap:	Steel tin plated
Bottom Endcap:	Steel tin plated
Inner Support Cylinder:	Steel zinc plated
Filter Media:	Multilayer fiberglass with epoxy coated mesh on both sides

Calculated Performance Criteria

Differential Pressure (Δp):	bar @ l/min
Tested to ISO3968 @ 32 cSt	psi @ gpm
Efficiency	>Beta 200 @ 5 microns & greater >Beta 1000 @ 7 microns & greater
Minimum Collapse Pressure:	>20 bar
Tested to ISO2941	>290 psi
Dirt Holding Capacity acc. to ISO16889	