


Interchange Element Data Sheet

Data sheet created using the Parker Par Fit Toolkit software.

Creation Date:	05/09/2018
Datasheet No:	
Parker Part No:	940369Q
OEM:	MP Filtri
OEM Part No:	CU4005A10AN

Product Dimensions

A (mm)	101.1	(inch)	3.98
B (mm)	60.5	(inch)	2.38
C (mm)	60.5	(inch)	2.38
D (mm)	101.1	(inch)	3.98
E (mm)	656.6	(inch)	25.85

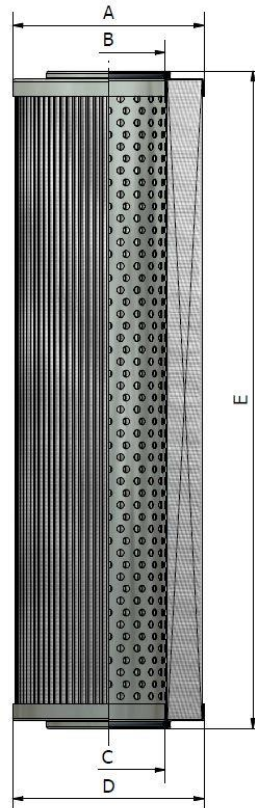

Construction Materials

Seal(s):	FKM: Fluorocarbon
Top Endcap:	Steel
Bottom Endcap:	Steel
Inner Support Cylinder:	Steel
Filter Media:	Multilayer fiberglass with epoxy coated mesh on both sides

Calculated Performance Criteria

Differential Pressure (Δp):	bar @ l/min
Tested to ISO3968 @ 32 cSt	psi @ gpm
Efficiency	>Beta 200 @ 9 microns & greater >Beta 1000 @ 12 microns & greater
Minimum Collapse Pressure:	>20 bar
Tested to ISO2941	>290 psi
Dirt Holding Capacity acc. to ISO16889	