

34"

HIGH VELOCITY FAN



standard YM - YOKE MOUNT

additional mounting options:

image not
available

CW - Column Wall



PB - Pedestal Base

Shipping Weight:

240 lbs/ 109 kg

SIZE	CFM	HP	FAN DIMENSIONS			DISTANCE AIR THROW	SHIPPING WEIGHT
			W	D	I.D.		
34"	17,000	3	43.5"	25.5"	34.9"	230' / 70 m	215 lbs/ 97.5 kg

Propeller: 34" Diameter, 3 Blade GalvAlum (15 Degree)

Fan Inlet/Outlet: 14 Gauge Spun Steel

Finger Guards: OSHA Standard, Spiral Wound Steel

RPM: 1200

Decibels: 88 @ 20'

Enclosure: TEAO Standard

Frame: 56

Ambient Temperature: 40C

Duty Cycle: Continuous

Power Cord: N/A

Coverage: 17,000 Sq.Ft. Max

Warranty: 2 Years

Voltage

208-230/ 460V*

Motor
Amps


9.9-9.2/ 4.6

Running
Amps

9.7-9.0/ 4.5

*standard


34" High Velocity Fan Air Flow Pattern

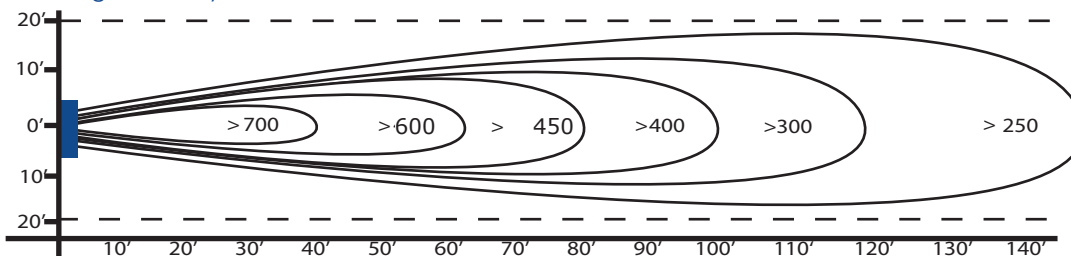

Above velocities shown in feet per minute.


MOUNTING OPTIONS

YOKE MOUNT STANDARD

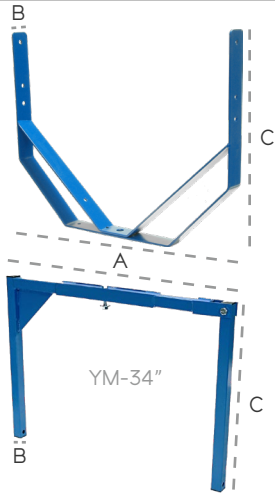


FAN SIZE	MOUNT DIMENSIONS			SHIPPING WEIGHT
	A	B	C	
14"	14"	2"	14"	4 lbs
18"	19.5"	2"	14.5"	8 lbs
22"	24"	2"	18"	10 lbs
26"	28"	4"	19.5"	21 lbs
30"	30.5"	4"	20.75"	24 lbs
34"	36"	2"	29"	25 lbs

TRUCK COOLER DOCK DOOR MOUNT

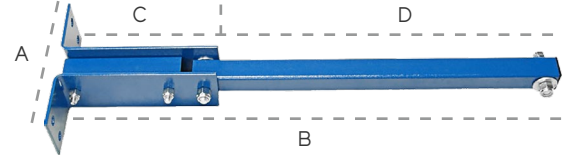

MOUNT DIMENSIONS				SHIPPING WEIGHT
A	B	C	D	
10.5"	36"	11"	25"	16 lbs


COLUMN-WALL

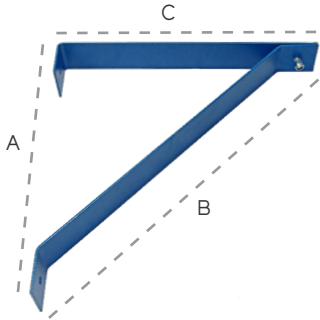

FAN SIZE	MOUNT DIMENSIONS			SHIPPING WEIGHT
	A	B	C	
10"	14"	19"	14"	4 lbs
14-22"	22"	30.5"	22"	13 lbs
26-30"	27"	38"	29"	20 lbs
34"	36"	43"	30"	24 lbs


OSCILLATORS AVAILABLE

RACK MOUNT PICK MODULE FANS

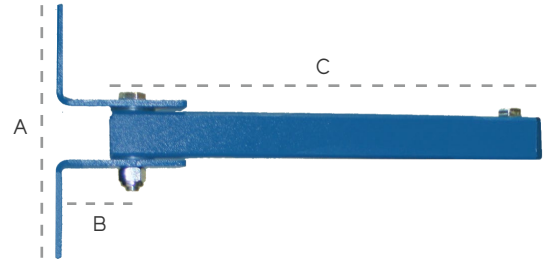

FAN SIZE	MOUNT DIMENSIONS			SHIPPING WEIGHT
	A	B	C	
14"	10.5"	3"	14.5"	5 lbs
18"	10.5"	3"	17"	7 lbs
22"	10.5"	3"	19"	8 lbs
26-30"	10.5"	3"	21"	10 lbs

PORTABLE STROLLER

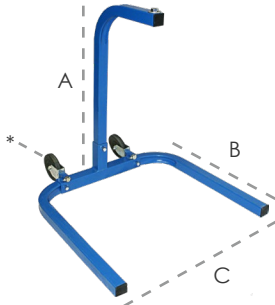


FAN SIZE	MOUNT DIMENSIONS			SHIPPING WEIGHT
	A	B	C	
14-30"	32"	35"	32"	36 lbs

* 5" Caster Wheels


OSCILLATORS AVAILABLE

PEDESTAL BASE

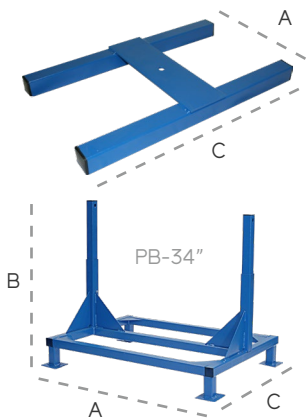

FAN SIZE	MOUNT DIMENSIONS			SHIPPING WEIGHT
	A	B	C	
14"	12"	-	14.5"	6 lbs
18-22"	15"	-	23"	12 lbs
26"	16"	-	26"	15 lbs
30"	20"	-	26"	15 lbs
34"	41.5"	32.5"	28.5"	106 lbs

BEAM CLAMP

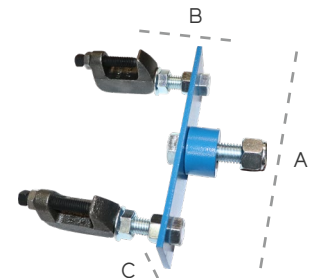

FAN SIZE	MOUNT DIMENSIONS			SHIPPING WEIGHT
	A	B	C	
14-30"	7"	3"	2"	3 lbs