

14"

HIGH VELOCITY FAN



STANDARD YM - YOKE MOUNT

ADDITIONAL MOUNTING OPTIONS:



RM Rack Mount



TC Truck Cooler



CW Column-Wall



PS Portable Stroller



PB Pedestal Base

SHIPPING WEIGHTS:

40 lbs

51 lbs

48 lbs

71 lbs

41 lbs

SIZE

CFM

HP

FAN DIMENSIONS

W

D

ID

AIR THROW
DISTANCE

SHIPPING
WEIGHT

14"

2600

1/4

20"

16"

14.625"

60'

35 lbs

FEATURES

Propeller: 14" Diameter, 3 Blade GalvAlum, 37°
Fan Inlet/Outlet: High Impact Polypropylene
Finger Guards: OSHA Compliant, Spiral Wound Steel
Power Cord (115V Only): 12' Length
RPM: 1725
Decibels: 66.5 @ 20' - 73.9 @ 3'
Coverage: 1800 ft²

Warranty: 2 Years

MOTOR

VOLTAGE

MOTOR
AMPS

RUNNING
AMPS

115V/208-230V*

2.8/1.4

2.8/1.4

208-230/460V

1.5-1.4/.75

1.4/.70

277V

1.1

1.1


Enclosure: TEAO Standard

Frame: 48

Ambient Temperature: 104°F

Duty Cycle: Continuous

*standard

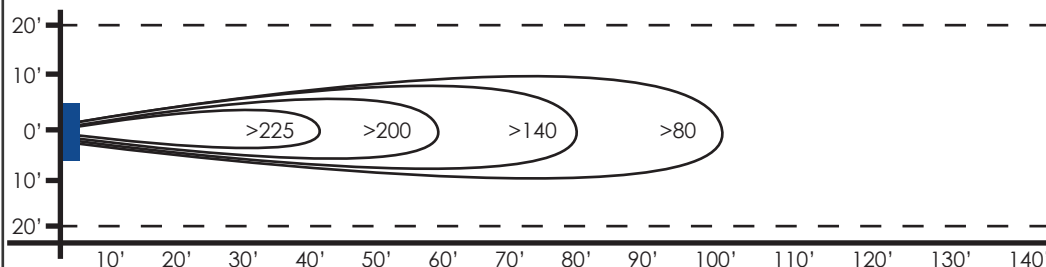

Above velocities shown in feet/minute.

AIR FLOW PATTERN

