

18"

HIGH VELOCITY FAN



STANDARD YM - YOKE MOUNT

ADDITIONAL MOUNTING OPTIONS:



RM Rack Mount



TC Truck Cooler



CW Column-Wall



PS Portable Stroller



PB Pedestal Base

SHIPPING WEIGHTS:

51 lbs

60 lbs

57 lbs

80 lbs

56 lbs

SIZE

CFM

HP

FAN DIMENSIONS

W

D

ID

AIR THROW
DISTANCE

SHIPPING
WEIGHT

18"

3800

1/2

24"

16"

19.125"

80'

44 lbs

FEATURES

Propeller: 17" Diameter, 3 Blade GalvAlum, 33°

Fan Inlet/Outlet: High Impact Polypropylene

Finger Guards: OSHA Compliant, Spiral Wound Steel

Power Cord (115V Only): 12' Length

RPM: 1725

Decibels: 71.2 @ 20' - 77.9 @ 3'

Coverage: 2700 ft²

Warranty: 2 Years

MOTOR

VOLTAGE

MOTOR
AMPS

RUNNING
AMPS

115V/208-230V*

6.0/3.0-2.9

5.9/2.9-2.8

208-230/460V

2.11-1.91/.96

2.0-1.8/.9

277V

1.85

1.75


Enclosure: TEAO Standard

Frame: 56

Ambient Temperature: 104°F

Duty Cycle: Continuous

*standard

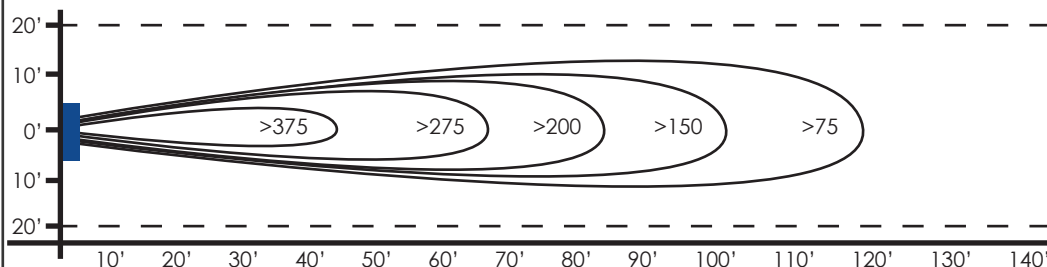

AIR FLOW PATTERN

Above velocities shown in feet/minute.

