






**MICRO GEAR PUMP
80 WATT BLDC MOTOR
G1/8 (BSPP) PORTS**

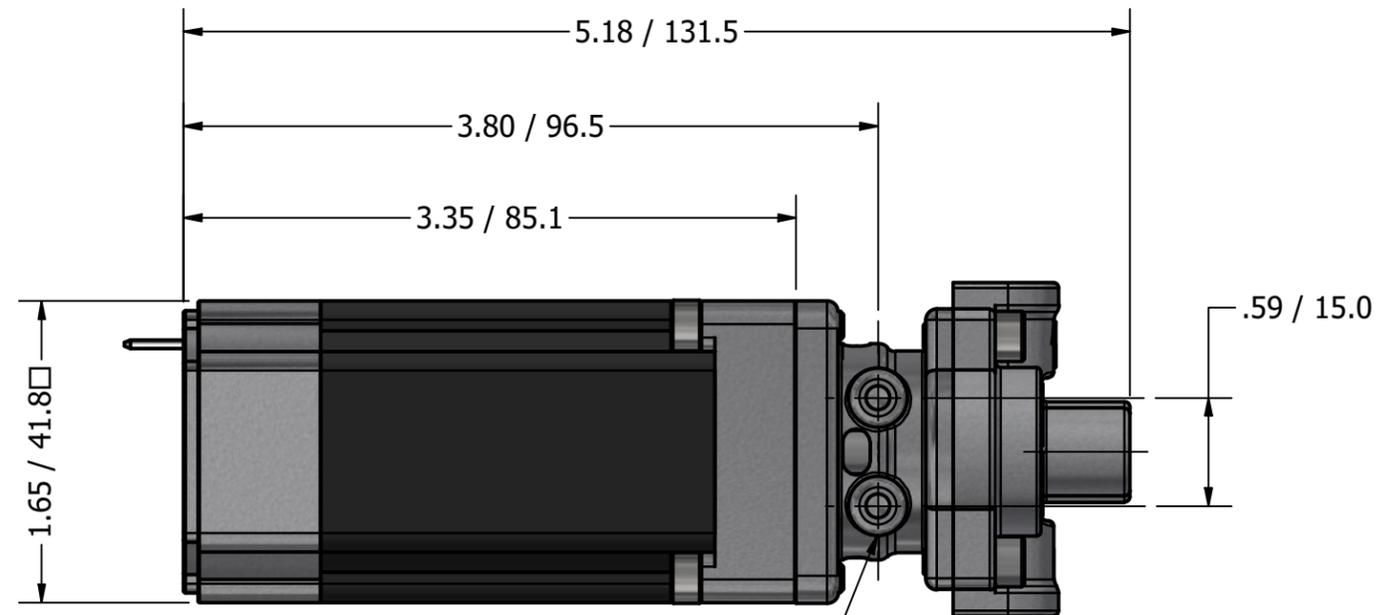

M4 X 0.7 X .236± .01 / 5.99± 0.3 DEEP
4 PLCS

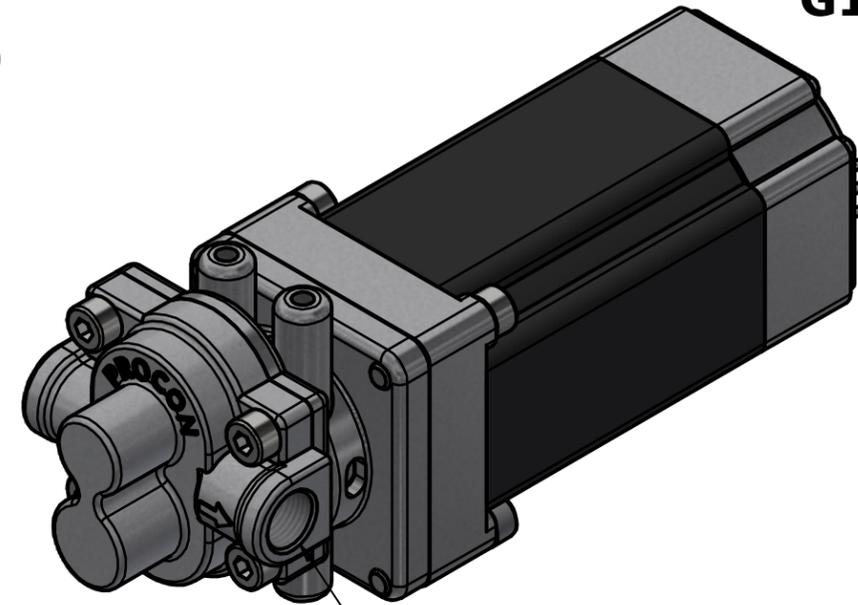


G1/8 (BSPP)
INLET/OUTLET PORTS

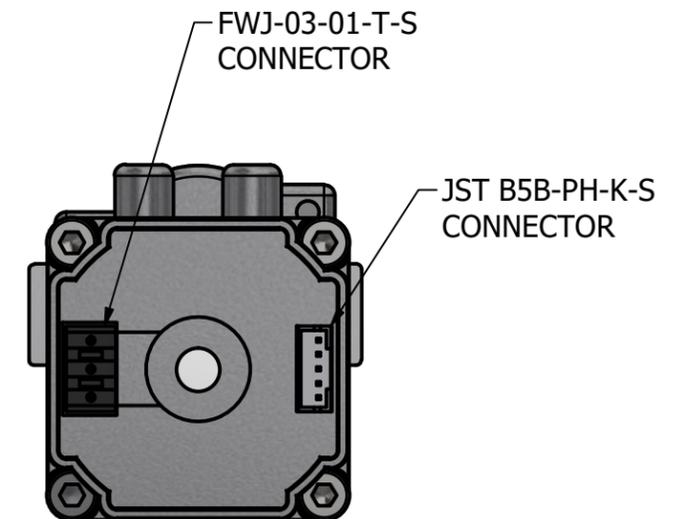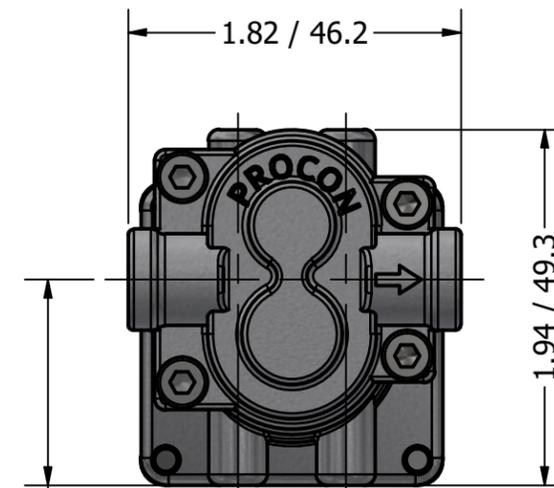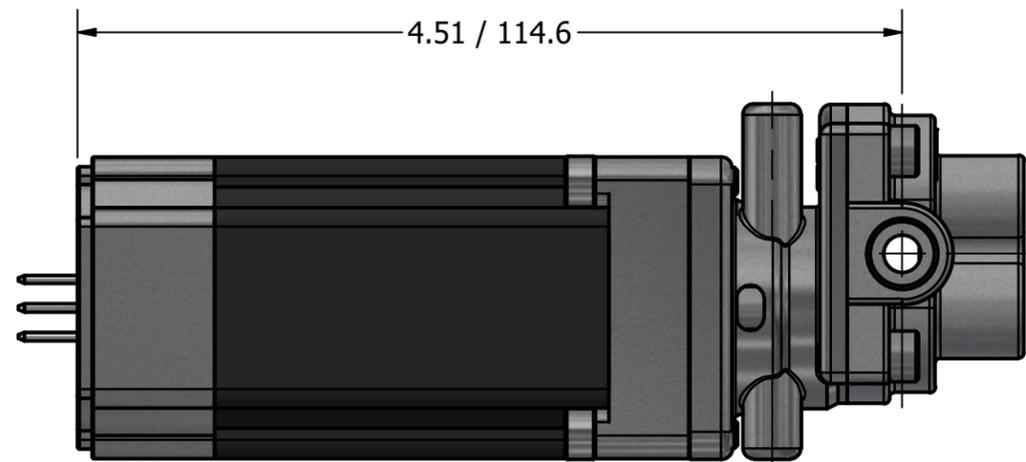

PROCON[®]
custom | fluid | solutions[®]

W5004 v2

Gear Pump Performance with 24VDC Brushless Motor

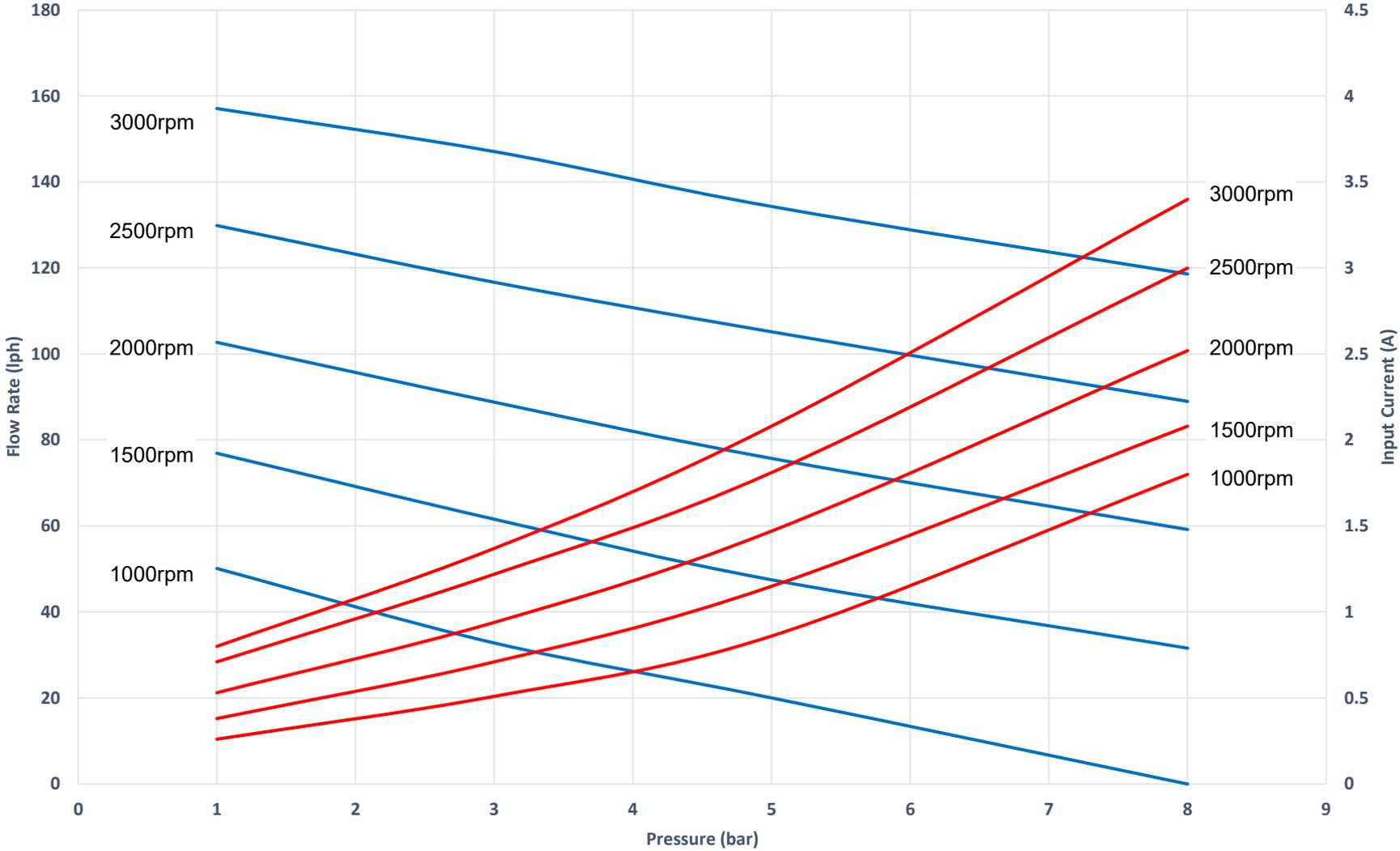

— Flow Rate — Input Current