


## Stackers - Heavy-Duty Straight Wall Stacking Container

Heavy-duty, straight wall containers maximize your space when used for shipping, storage or work-in progress. Greater strength and durability provided by reinforced corners allowing this strong container to hold the heaviest of parts. Containers are injection molded from high-density polyethylene. Straight wall design allows for modular stacking of all sizes on standard pallets. Hand grips on two sides make the container easy to handle and carry. Up to 175 lb. stack capacity.

Available in: ● Gray


| MODEL NO.   | OUTSIDE DIMENSIONS L" x W" x H" | INSIDE DIMENSIONS L" x W" x H" | CTN QTY | VOLUME (CU FT) | SHIP WGT | LID     |
|-------------|---------------------------------|--------------------------------|---------|----------------|----------|---------|
| RS01207-5   | 12" x 7-1/2" x 5"               | 9-3/4" x 5-1/2" x 4-7/8"       | 1       | 0.1            | 2 lbs    | -       |
| RS01215-5   | 12" x 15" x 5"                  | 9-1/2" x 13" x 4-7/8"          | 1       | 0.3            | 2 lbs    | LID1215 |
| RS01215-7   | 12" x 15" x 7-1/2"              | 9-1/2" x 13" x 7"              | 1       | 0.5            | 3 lbs    | LID1215 |
| RS02415-5   | 24" x 15" x 5"                  | 21-1/2" x 13" x 4-7/8"         | 1       | 0.7            | 4 lbs    | LID2415 |
| RS02415-7   | 24" x 15" x 7-1/2"              | 21-1/2" x 13" x 7"             | 1       | 1.1            | 5 lbs    | LID2415 |
| RS02415-9   | 24" x 15" x 9-1/2"              | 21-1/2" x 13" x 9"             | 1       | 1.4            | 5 lbs    | LID2415 |
| RS02422-11* | 24" x 22-1/2" x 11"             | 21-1/2" x 20-1/2" x 10-1/4"    | 1       | 3.5            | 8 lbs    | -       |

\*Cannot be used on DLY-2415. Use with DLY-3018 Dolly.

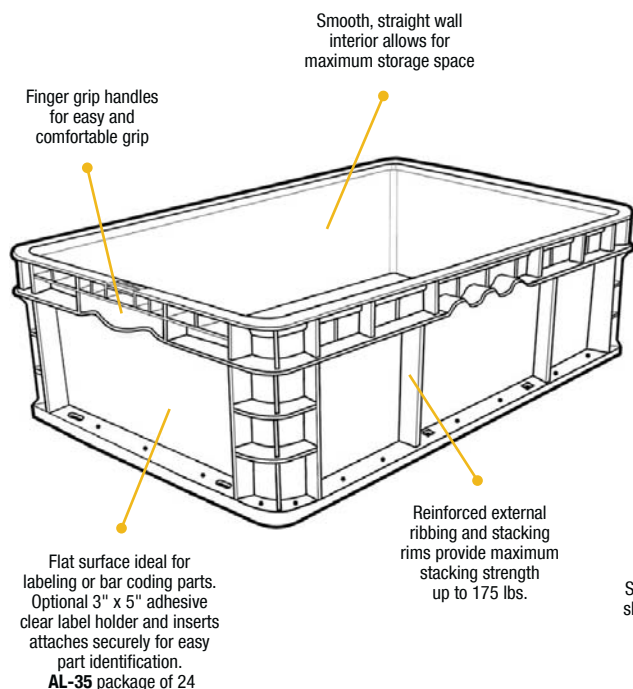

RS02422-11

Straight Wall container shown with optional lid LID2415 (Sold separately)

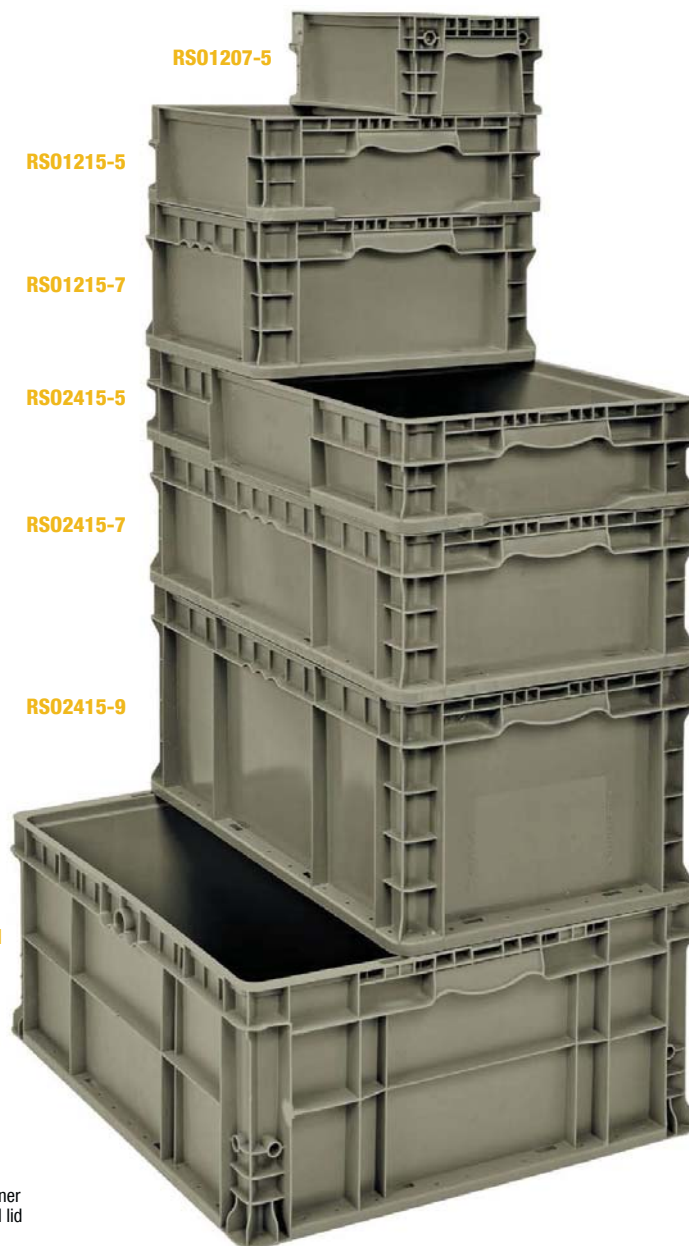

## MOBILIZE YOUR BINS

### Polymer Dollies

DLY-2415 is 24"L x 15"W with 1" Ledge, available in Black.

DLY-3018 is 30"L x 18"W with padded rubber trim, available in Blue.

Set of four 4" x 1-1/4" non-marking swivel poly casters.

Both dollies have 1,000 lb. load capacity.

| MODEL NO. | DESCRIPTION                   | CTN WGT |
|-----------|-------------------------------|---------|
| DLY-2415  | Dolly with 1" Ledge           | 14 lbs  |
| DLY-3018  | Dolly with Padded Rubber Trim | 19 lbs  |

Bins sold separately



DLY-2415

Interior Dimensions 24"L x 15"W  
Exterior Dimensions 28"L x 18-1/2"W