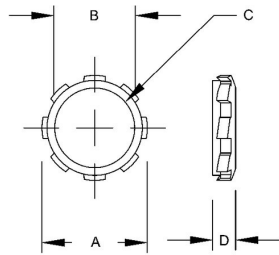


**SEALING LOCKNUTS****Sealing Locknuts Steel****B38**

Catalog #: 1208

APPLICATIONS

For use on threaded rigid/IMC conduit to provide a liquidtight seal against water and oil
RACO sealing locknuts may be used with either sheet metal or cast enclosures

PRODUCT FEATURES

Fused-in-place gasket guarantees a liquidtight seal
Use RACO sealing locknuts as an economical alternative to a threaded enclosure connector
All steel construction insures mechanical protection
Zinc electro plated for corrosion protection
N/A

UL LISTED

Standard 514B (part numbers 1202-1210), UL File E195969

CSA

C22.2 No. 18 (part numbers 1202-1211)

COMPLIANCES

MSDS
www.hubbell-rtb.com/certifications/Hubbell-RACO_MSDS_for_WP_Boxes_and_Fittings,January_2015.pdf

GENERAL PRODUCT INFORMATION

Trade Size: 2 in.

DRAWING DIMENSIONS

Dimension A: 2-29/32 in.
Dimension B: 2-5/16 in.
Thread Spec. C: 2 in. - 11-1/2 NPT
Dimension D: 19/64 in.

PACKAGING

Package Type: Carton
Ship Carton Qty.: 25
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 5.00
Ship Carton Length (in.): 6.25
Ship Carton Width (in.): 4.50
Ship Carton Height (in.): 4.25
Ctn Weight (Lbs.): 3.25
UPC Number: 050169012086
I2of5: 50050169012081