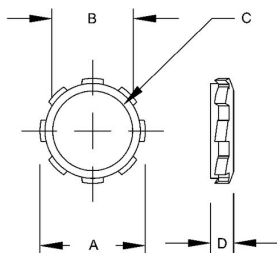


**SEALING LOCKNUTS****Sealing Locknuts Steel**
N/A**B38**

Catalog #: 1211

APPLICATIONS

For use on threaded rigid/IMC conduit to provide a liquidtight seal against water and oil
RACO sealing locknuts may be used with either sheet metal or cast enclosures

PRODUCT FEATURES

Fused-in-place gasket guarantees a liquidtight seal
Use RACO sealing locknuts as an economical alternative to a threaded enclosure connector
All steel construction insures mechanical protection
Zinc electro plated for corrosion protection
N/A

UL LISTED

Standard 514B (part numbers 1202-1210), UL File E195969

CSA

C22.2 No. 18 (part numbers 1202-1211)

GENERAL PRODUCT INFORMATION

Trade Size: 4 in.

DRAWING DIMENSIONS

Dimension A: 5-9/32 in.
Dimension B: 4-13/32 in.
Thread Spec. C: 4 in. - 8 NPT
Dimension D: 3/8 in.

PACKAGING

Package Type: Carton
Ship Carton Qty.: 10
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 25.80
Ship Carton Length (in.): 5.51
Ship Carton Width (in.): 5.00
Ship Carton Height (in.): 4.33
Ctn Weight (Lbs.): 2.58
UPC Number: 050169012116
I2of5: 50050169012111