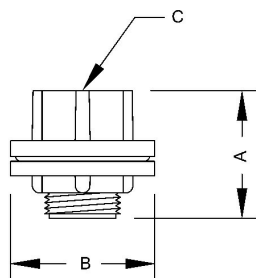


**RIGID THREADED HUBS - DIE CAST ZINC****Conduit Hub, Insulated Throat Die Cast Zinc**
N/A**B33**

Catalog #: 1714

APPLICATIONS

For use with threaded rigid/IMC conduit to connect and bond conduit to a threadless opening in a box or enclosure
May be used in wet or dry locations

PRODUCT FEATURES

Rugged metallic construction insures mechanical protection
Insulated throat protects wires and reduces wire pulling effort
O-ring seals the assembly and provides a raintight seal
N/A

UL LISTED

Standard 514B, UL Listed E195969

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Trade Size: 3-1/2 in.

DRAWING DIMENSIONS

Dimension A: 2.570 in.
Dimension B: 4.941 in.
Dimension C: 3-1/2 in. - 8 NPT

PACKAGING

Package Type: Carton
Ship Carton Qty.: 2
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 300.00
Ship Carton Length (in.): 10.00
Ship Carton Width (in.): 5.25
Ship Carton Height (in.): 4.31
Ctn Weight (Lbs.): 6.00
UPC Number: 050169017142
I2of5: 50050169017147