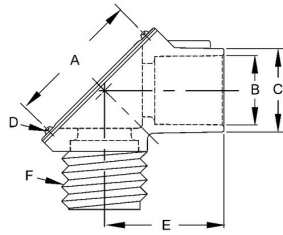


**RIGID HANDY ELLS - DIE CAST ZINC****90 Degree Threaded Handy Ells Male-Female Die Cast Zinc**
N/A**B29**

Catalog #: 2663

APPLICATIONS

For use to bond rigid/IMC conduit to a box or enclosure
Use handy ells when bending conduit is not practical

PRODUCT FEATURES

N/A

UL LISTED

Standard 514B, UL Listed E195969

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Trade Size: 3/4 in.

DRAWING DIMENSIONS

Dimension A: 1-13/16 in.
Dimension B: 3/4 in. - 14 NPSM
Dimension C: 1-15/64 in.
Dimension D: 8 - 32 x 1/4 in.
Dimension E: 1-13/32 in.
Dimension F: 3/4 in. - 14 NPSM

PACKAGING

Package Type: Carton
Std. Pkg.: 5
Ship Carton Qty.: 50
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 22.60
Ship Carton Length (in.): 19.00
Ship Carton Width (in.): 10.63
Ship Carton Height (in.): 4.13
Ctn Weight (Lbs.): 11.30
UPC Number: 050169026632
I2of5: 50050169026637