




CEILING PANS

1/2 in. Deep, 3-1/2 in. Round Ceiling Pan - Drawn with Nonmetallic Sheathed Cable Clamps

A36.1

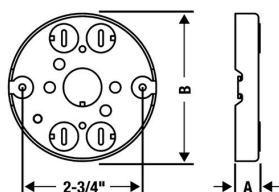

Catalog #: 292

APPLICATIONS

RACO® Ceiling Pans are used in the installation of ceiling or wall lighting fixtures

PRODUCT FEATURES

Combination screw heads provide for faster installation

UL LISTED

File E195978

COMPLIANCES

MSDS
www.hubbell-rtb.com/certifications/Hubbell-RACO_MSDS_for_Steel_Boxes_and_Covers.pdf

US PATENTS

7,148,420; 4,892,211

OTHER PATENTS

Canada 1,324,360; Mexico 166.125

GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable

RECOMMENDED MAX LOAD

Ceiling Fan (Dynamic) Lbs.: No
Fixture (Static) Lbs.: 50

CONFIGURATION

Cable Priouts: 4
Drawn or Welded: Drawn
Raised Ground: No
Side Knockout(s): ---
Bottom Knockouts(s): (1) 1/2 in.

DRAWING DIMENSIONS

Dimension A: 1/2 in.
Dimension B: 3-3/8 in.

PRODUCT MEASUREMENTS

Depth: 1/2 in.
Cubic Inches (cm3): 4.0 (65.5)
Wt. Ea. (Lbs.): 0.296
Product Length (in.): 0.56
Product Width (in.): 3.38
Product Height (in.): 3.38

PACKAGING

Minimum Pack Qty.: 50
Std. Pkg.: 50
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 29.60
Ship Carton Length (in.): 11.50
Ship Carton Width (in.): 5.00
Ship Carton Height (in.): 9.25
Ctn Weight (Lbs.): 14.80

Pallet Qty:	7200
UPC Number:	050169902929
I2of5:	50050169902924