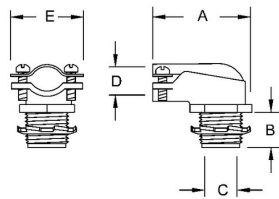


**FLEXIBLE METAL 90 DEGREE SQUEEZE CONNECTORS****90° Squeeze Connectors Malleable Iron**
N/A**B63**

Catalog #: 3208

APPLICATIONSFor use in dry locations to bond flexible metal conduit to a box or enclosure
N/A**PRODUCT FEATURES**

All malleable iron construction insures mechanical protection for the raceway
Electro zinc plated for added corrosion protection
UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation

CULUS

UL Listed E195969

GENERAL PRODUCT INFORMATIONSub Class: Insulated
Trade Size: 2 in.**DRAWING DIMENSIONS**Dimension A: 6-35/64 in.
Dimension B: 51/64 in.
Thread Spec. B: 2 in. - 11-1/2 NPS
Dimension C: 1.883 in.
Dimension D: 2.415 in. MAX
Dimension E: 3-51/64 in.**PACKAGING**Package Type: Carton
Ship Carton Qty.: 5
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 312.50
Ship Carton Length (in.): 9.19
Ship Carton Width (in.): 8.25
Ship Carton Height (in.): 6.56
Ctn Weight (Lbs.): 15.63
UPC Number: 050169032084
I2of5: 50050169032089