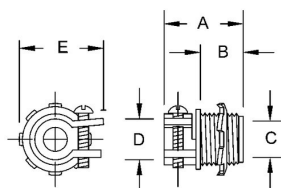


**FLEXIBLE METAL STRAIGHT SQUEEZE CONNECTORS****Straight Squeeze Connectors, Insulated Malleable Iron**
N/A**B61**

Catalog #: 3312

APPLICATIONSFor use in dry locations to bond flexible metal conduit to a box or enclosure
N/A**PRODUCT FEATURES**

All malleable iron construction insures mechanical protection for the raceway
Electro zinc plated for added corrosion protection
UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation

CULUS

UL Listed E195969

GENERAL PRODUCT INFORMATION

Trade Size: 3 in.

DRAWING DIMENSIONS

Dimension A: 3-15/64 in.
Dimension B: 1-5/64 in.
Thread Spec. B: 3 in. - 8 NPS
Dimension C: 2.29 in.
Dimension D: 3.645 MAX
Dimension E: 5 in.

PACKAGING

Package Type: Carton
Ship Carton Qty.: 1
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 204.60
Ship Carton Length (in.): 5.60
Ship Carton Width (in.): 5.20
Ship Carton Height (in.): 3.80
Ctn Weight (Lbs.): 2.05
UPC Number: 050169033128
I2of5: 50050169033123