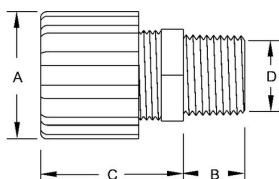


**STRAIN RELIEF CONDUIT AND CORD CONNECTORS - NONMETALLIC****Straight Strain Relief Connectors Nylon**
N/A**B59**

Catalog #: 4704-5

APPLICATIONS

For use in dry or wet locations to provide a liquidtight and strain relief termination for flexible cord and cable
RACO liquidtight strain relief cord connectors are suitable for use in Class I, Div. 2; Class II, Div. 1 & 2; and Class III, Div. 1 & 2 hazardous locations

PRODUCT FEATURES

Nylon construction is lightweight and easy to use
Neoprene grommet
Resists most common industrial corrosives
Color-coded Gotcha[®] ring provides fast identification of cord size
N/A

UL LISTED

Standard 514B

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Trade Size:	1 in.
Cable Range:	.875 - 1.000
Color Code:	Gray
Form Size:	4

DRAWING DIMENSIONS

Dimension A:	1-27/32 in.
Dimension B:	11/16 in.
Dimension C:	1-3/4 in.
Dimension D:	1-1/64 in.

PACKAGING

Package Type:	Carton
Ship Carton Qty.:	10
Product UPC-A Labeled:	No
Weight (Lbs. Per/C):	15.60
Ship Carton Length (in.):	8.75
Ship Carton Width (in.):	5.00
Ship Carton Height (in.):	4.00
Ctn Weight (Lbs.):	1.56
UPC Number:	050169470459
I2of5:	50050169470454