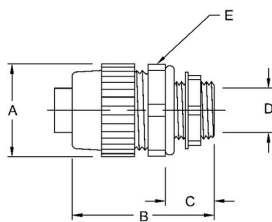


**TYPE B CONDUIT AND CORD CONNECTORS - NONMETALLIC****Straight Connector, Type B - Nylon**
N/A**B54**

Catalog #: 4725

APPLICATIONS

For use in dry or wet locations when the conduit and fittings are not subject to physical damage
Use Type B conduit and fittings whenever flexibility is required for installation, operation, or maintenance

PRODUCT FEATURES

All gray nonmetallic construction provides superior corrosion protection
Each connector is supplied with a Neoprene O-ring and nylon locknut
UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation
N/A

UL LISTED

Standard 514B

CSA

C22.2 No. 18

NEMA

NEMA Type 4x, 12 and 13

GENERAL PRODUCT INFORMATION

Trade Size: 1-1/4 in.

DRAWING DIMENSIONS

Dimension A: 2.20 in.
Dimension B: 2.15 in.
Dimension C: .74 in.
Dimension D: 1.30 in.
Dimension E: A/C 2.38 in., A/F 2.18 in.

PACKAGING

Package Type: Carton
Ship Carton Qty.: 10
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 18.00
Ship Carton Length (in.): 9.00
Ship Carton Width (in.): 7.25
Ship Carton Height (in.): 4.63
Ctn Weight (Lbs.): 1.00
UPC Number: 050169047255
I2of5: 50050169047250