




SWIVEL-LOK TYPE B CONDUIT AND CORD CONNECTORS

Straight to 90° Type B Swivel Lok® Connector, Nylon
N/A

B55

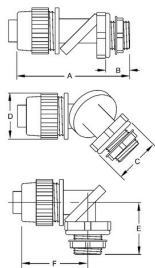

Catalog #: 4731

APPLICATIONS

For use in dry or wet locations when the conduit and fittings are not subject to physical damage
Use Type B conduit and fittings whenever flexibility is required for installation, operation, or maintenance

PRODUCT FEATURES

All gray nonmetallic construction provides superior corrosion protection
Each connector is supplied with a Neoprene O-ring and nylon locknut
UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation
SWIVEL-LOK® multi-position connector (trade sizes 3/8 in. to 1 in.) twists from 0° to 90°, easing installation in difficult locations and eliminating the need to stock other angle connectors
N/A

UL LISTED

Standard 514B

CSA

C22.2 No. 18

NEMA

NEMA Type 4x, 12 and 13

COMPLIANCES

MSDS
www.hubbell-rtb.com/certifications/Hubbell-RACO MSDS for WP Boxes and Fittings, January 2015.pdf

GENERAL PRODUCT INFORMATION

Trade Size: 3/8 in.

DRAWING DIMENSIONS

Dimension A: 3.27 in.
Dimension B: .57 in.
Dimension C: A/C 1.41 in., A/F 1.30 in.
Dimension D: 1.30 in.
Dimension E: 1.43 in.
Dimension F: 2.00 in.

PACKAGING

Package Type: Carton
Ship Carton Qty.: 25
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 2.80
Ship Carton Length (in.): 10.00
Ship Carton Width (in.): 5.25
Ship Carton Height (in.): 4.31
Ctn Weight (Lbs.): 0.70
UPC Number: 050169047316
I2of5: 50050169047311