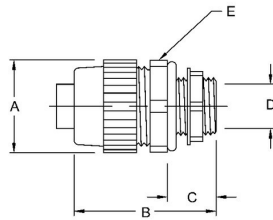


**EXTRA FLEXIBLE CONDUIT AND CORD CONNECTORS - NONMETALLIC****Straight Extra Flexible Tubing Connector, Nylon**
N/A**B56**

Catalog #: 4745

APPLICATIONS

For use in dry or wet locations when the conduit and fittings are not subject to physical damage
Use extra flexible tubing and connectors whenever added flexibility is required for installation, operation, or maintenance

PRODUCT FEATURES

All black nonmetallic construction ends metal fatigue and separation problems, and provides superior corrosion resistance
Each connector is supplied with a Neoprene O-ring and nylon locknut
SWIVEL-LOK[®] multi-position connector (trade sizes 3/8 in. to 1 in.) twists from 0° to 90°, easing installation in difficult locations and eliminating the need to stock other angle connectors
N/A

UL LISTED

Standard 514B

CSA

C22.2 No. 18

NEMA

NEMA Type 4x, 12 and 13

GENERAL PRODUCT INFORMATION

Trade Size: 1-1/4 in.

DRAWING DIMENSIONS

Dimension A: 2.20 in.
Dimension B: 2.15 in.
Dimension C: .74 in.
Dimension D: 1.30 in.
Dimension E: A/C 2.38 in., A/F 2.18 in.

PACKAGING

Package Type: Carton
Ship Carton Qty.: 10
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 10.00
Ship Carton Length (in.): 9.00
Ship Carton Width (in.): 7.25
Ship Carton Height (in.): 4.63
Ctn Weight (Lbs.): 1.00
UPC Number: 050169047453
I2of5: 50050169047458