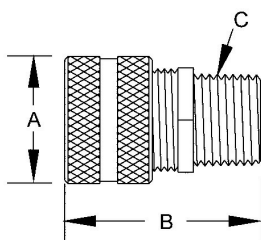


**LIQUIDTIGHT UF CONNECTORS****Underground Feeder, Liquidtight - Nylon**
N/A**B79**

Catalog #: 4799-3

APPLICATIONSFor use with underground feeder (UF) cable to provide a liquidtight connection to meters and enclosures
N/A**PRODUCT FEATURES**

Rugged metallic construction will last the life of the installation

UL LISTED

Standard 514B

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Trade Size:	3/4 in.
Min Grommet Opening:	.20 in. x .60 in.
Max Grommet Opening:	.26 in. x .78 in.
UF Wire Size:	3#14; 3#12; 3#10

DRAWING DIMENSIONS

Dimension A:	1.56 in.
Dimension B:	2.15 in.
Dimension C:	3/4 in. - 14

PACKAGING

Package Type:	Carton
Ship Carton Qty.:	15
Product UPC-A Labeled:	No
Weight (Lbs. Per/C):	11.20
Ship Carton Length (in.):	8.75
Ship Carton Width (in.):	5.00
Ship Carton Height (in.):	4.00
Ctn Weight (Lbs.):	1.68
UPC Number:	050169479933
I2of5:	50050169479938