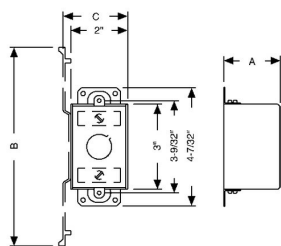


**3 IN. X 2 IN. SWITCH BOXES - 2-3/4 TO 3-1/2 IN. DEEP WITH NONMETALLIC SHEATHED CABLE CLAMPS****3-1/2 in. Deep Switch Boxes - Gangable with Nonmetallic Sheathed Cable Clamps
Plaster Ears, With Ground Screw Driven****A51**

Catalog #: 601G

APPLICATIONS

RACO[®] Switch boxes are used to house wiring devices such as switches and outlets
N/A

PRODUCT FEATURES

Gangable switch boxes offer the option of constructing a box to hold two or more devices
Plaster ears allow a box to be used in "old work" applications

UL LISTED

File E195978

COMPLIANCES

All RACO[®] single gang, two gang, 4 in. square, and single gang gangable UL listed steel boxes are acceptable for use in 2-hour fire rated walls. For additional information, consult UL "Fire Resistance Directory" or the UL website at www.ul.com

FIRE RESISTANCE

Acceptable for use in 2-hour rated walls

GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable

CONFIGURATION

End Knockouts: (2) 1/2 in.
Ends Cable: 4
Bracket Type: No Bracket
Side Knockout(s): (4) 1/2 in.
Bottom Knockouts(s): (1) 1/2 in.

DRAWING DIMENSIONS

Dimension A: 3-1/2 in.

PRODUCT MEASUREMENTS

Depth: 3-1/2 in.
Cubic Inches (cm³): 18.0 (295.0)
Wt. Ea. (Lbs.): 0.778
Product Length (in.): 3.50
Product Width (in.): 4.22
Product Height (in.): 2.00

PACKAGING

Minimum Pack Qty.: 25
Std. Pkg.: 25
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 77.80
Ship Carton Length (in.): 11.13
Ship Carton Width (in.): 8.50
Ship Carton Height (in.): 10.00
Ctn Weight (Lbs.): 19.45
Pallet Qty: 2000
UPC Number: 050169506011
I2of5: 50050169506016