




WELDED GANG BOXES WITH CONDUIT KO'S

Gang Boxes, 2-1/2 in. Deep - Welded with Conduit KO's
2-Gang

A54

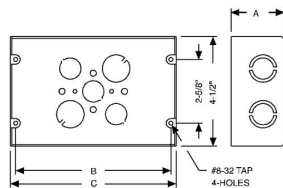

Catalog #: 941

APPLICATIONS

RACO[®] Gang boxes are used where a number of wiring devices are to be centrally located
N/A

PRODUCT FEATURES

Gang boxes save time in installation, no need to gang boxes together
Have 3/4" and 1" concentric KO's for use with a wide variety of wiring methods
Bottom KO pattern, 3-1/2" and 2-3/4" at either end of box
Accepts two styles of covers, flat and 3/4" raised device cover
Use low voltage partitions #947 or #949

UL LISTED

File E195978

GENERAL PRODUCT INFORMATION

Wiring System: Conduit

CONFIGURATION

Top & Bottom Knockouts(s): (4) 3/4, (4) 3/4-1 in. Concentric
Back Knockout(s): (3) 1/2 in. & (2) 3/4 in.
Gangs: 2
Side Knockout(s): (4) 3/4-1 in. Concentric

DRAWING DIMENSIONS

Dimension A: 2-1/2 in.
Dimension B: 6-3/8 in.
Dimension C: 6-13/16 in.

PRODUCT MEASUREMENTS

Depth: 2-1/2 in.
Cubic Inches (cm3): 70.0 (1147.0)
Wt. Ea. (Lbs.): 1.625
Product Length (in.): 2.50
Product Width (in.): 4.50
Product Height (in.): 6.81

PACKAGING

Minimum Pack Qty.: 5
Std. Pkg.: 5
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 162.50
Ship Carton Length (in.): 7.25
Ship Carton Width (in.): 9.50
Ship Carton Height (in.): 7.75
Ctn Weight (Lbs.): 8.13
Pallet Qty: 600
UPC Number: 050169009413
I2of5: 50050169009418