


Model without Hose & Bumper	Finish	Spool Width	Shipping Weight		Max Pressure	
			lbs	kg	psi	bar
Hand Crank Medium Pressure Reels			Maximum Temperature 150°F (65°C) Maximum Working Pressure is at 70°F (20°C)			
C23012	Powder Coated	12"	21.5	10	3000	207
C23018	Powder Coated	18"	23.5	10	3000	207
C23022	Powder Coated	22"	25	11	3000	207
C23012 310	Tumbled Natural	12"	21.5	10	3000	207
C23018 310	Tumbled Natural	18"	23.5	10	3000	207
C23022 310	Tumbled Natural	22"	25	11	3000	207
12 V DC Motor Driven Medium Pressure Reels			Maximum Temperature 150°F (65°C) Maximum Working Pressure is at 70°F (20°C)			
E23012	Powder Coated	12"	24.5	11	3000	207
E23018	Powder Coated	18"	26.5	12	3000	207
E23022	Powder Coated	22"	28	13	3000	207
E23012 310	Tumbled Natural	12"	24.5	11	3000	207
E23018 310	Tumbled Natural	18"	26.5	12	3000	207
E23022 310	Tumbled Natural	22"	28	13	3000	207
Hand Crank High Pressure Reels			Maximum Temperature 210°F (99°C) Maximum Working Pressure is at 70°F (20°C)			
C23012 H	Powder Coated	12"	21.5	10	4500	310
C23018 H	Powder Coated	18"	23.5	10	4500	310
C23022 H	Powder Coated	22"	25	11	4500	310
C23012 H 310	Tumbled Natural	12"	21.5	10	4500	310
C23018 H 310	Tumbled Natural	18"	23.5	10	4500	310
C23022 H 310	Tumbled Natural	22"	25	11	4500	310
12 V DC Motor Driven High Pressure Reels			Maximum Temperature 210°F (99°C) Maximum Working Pressure is at 70°F (20°C)			
E23012 H	Powder Coated	12"	24.5	11	4500	310
E23018 H	Powder Coated	18"	26.5	12	4500	310
E23022 H	Powder Coated	22"	28	13	4500	310
E23012 H 310	Tumbled Natural	12"	24.5	11	4500	310
E23018 H 310	Tumbled Natural	18"	26.5	12	4500	310
E23022 H 310	Tumbled Natural	22"	28	13	4500	310

Medium pressure reels supplied with Stainless Steel 3000 psi swivel. High pressure reels supplied with Carbon Steel 4500 psi swivel.

Hose Diameter				
ID	3/8"	1/2"	5/8"	3/4"
OD	0.71"	0.85"	0.94"	1.08"
Spool Width	Hose Capacity			
12"	300'	200'	150'	125'
18"	500'	300'	250'	200'
22"	600'	350'	300'	250'

Dimensions - Width				
	Spool	12"	18"	22"
A	Motor Driven	28"	34"	38"
A	Hand Crank	25"	31"	35"
B	Mounting Pattern	16.88"	22.88"	26.88"
C	Mounting Pattern	11"	17"	21"
D	Mounting Pattern	18"	24"	28"

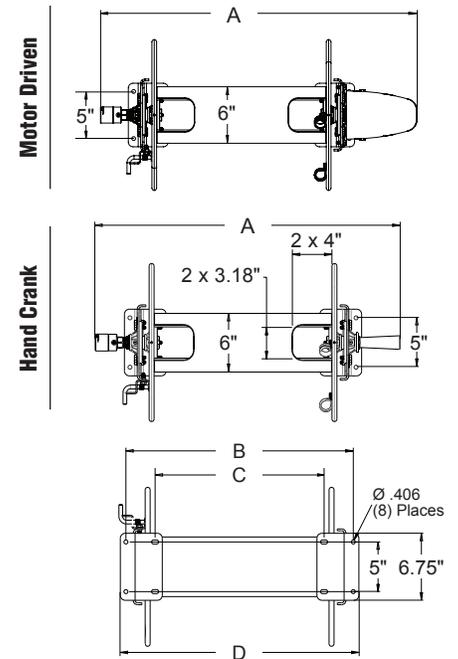

Optional Spray Reel Accessories See pages 38-39.



Side Wind Roller Guide Kit

Our SW Roller Guide Kit makes it easier to pull the hose at higher elevations.



Bottom Wind Roller Guide Kit

Our BW Roller Guide Kit makes it easier to pull the hose at lower elevations.



Stacking Brackets Kit

Stacking brackets are easy to install, allowing you to customize your setup to suit your needs.



Whip Hose—Chemical S602975

- 3/4" ID, Stainless Steel Ends
- 200 PSI



Whip Hose—Power Wash S602976

- 1/2" ID
- Plated Carbon Steel Ends
- 4300 PSI