


Spring Retractable Tool Balancers Series TB / TBL

- Balances the weight of assembly tools, making them nearly weightless
- Reduces tool damage by preventing tools from being accidentally dropped
- Increases productivity by keeping tools positioned for immediate use with minimal operator motion
- Reduces operator fatigue and improves safety and ergonomic



Model	Min - Max Load		Cable Length*		Shipping Weight		Ratchet Lock
	lbs	kg	ft	m	lbs	kg	
TB 01	0.0 - 1.5	0.0 - 0.7	6	1.8	1.0	0.5	NO
TB 03	1.5 - 3.0	0.7 - 1.4	6	1.8	1.0	0.5	NO
TB 05	3.0 - 5.0	1.4 - 2.3	6	1.8	1.5	1	NO
TBL 10	5.0 - 10	2.3 - 4.5	8	2.4	9	4	YES
TBL 15	10 - 15	4.5 - 6.8	8	2.4	10	4.5	YES
TBL 23	16 - 23	7.2 - 10.4	8	2.4	10	4.5	YES

*Cable lengths listed are "active" or "working" cable. Maximum temperature 150°F (65°C).

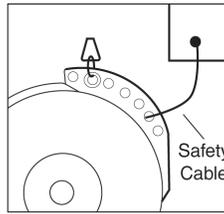


Bumper - S602413
Included with each model.

Strongly recommended, secondary steel cable or steel link chain. Prevents balancer from accidental fall. Balancers have extra holes for cable or chain.

Safety Cable/Chain (not included)	
600603*	1.0 ft / 30.5 cm
600604**	1.0 ft / 30.5 cm

Cables can be combined for added length *Nylon covered steel cable (1-6 lbs models)
**Steel link chain (10-23 lbs models)

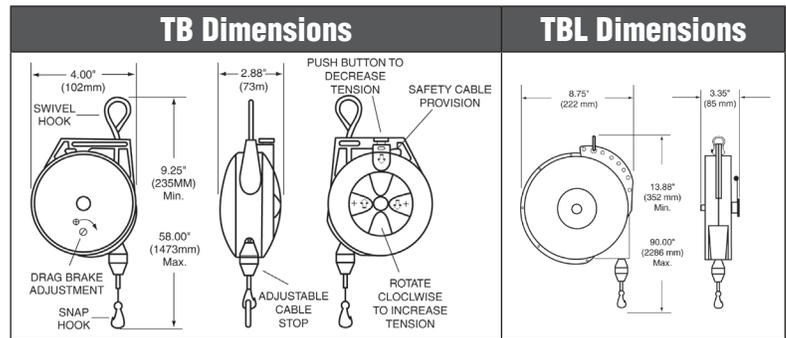

Adjustable Bumpers

Refer to page 26 for cord reel bumpers. Partial List - Visit Reelcraft.com for a complete list.

When ordering, advise the part number, reel model, and the hose I.D. and O.D. Refer to Reelcraft.com for dimensions.

NOTE: To order hose bumper with stainless steel hardware, change part number from HR to HS (not available with all models).

Part Number	For Reel Series	Hose / Cord O.D.		Hose I.D.		Weight		Overall Diameter	
		in	mm	in	mm	lbs	kg	in	mm
S1-HR1004-A	4000 / 5000 / RT400 / L4500 / L5000 / DP	.438 (11)	.625 (16)	1/4	6	.24	.10	2 1/2	64
S1-HR1004	4000 / 5000 / RT400 / RT600	.625 (16)	.749 (19)	3/8	10	.25	.11	2 1/2	64
S1-HR1004-3	7000 / 80000 / RT800 / 5000 / D80000 / DP	.625 (16)	.749 (19)	3/8	10	.24	.10	3	73
S2-HR1004-3	5000 / 5005 / 7000 / 80000 / RT800 / DP	.750 (19)	1.05 (27)	1/2 or 3/8	13 or 10	.23	.10	3	73
S3-HR1004-3	7000 / 80000 / L7000	1.06 (27)	1.38 (35)	3/4	19	.32	.14	3	73
S8-HR1004-3	TW5000 / TW7000 / TW80000	.530 (13)	twin	1/4	twin	.24	.10	3	73
S600193	L 4000 / L 5000 / L 7000 / L 70000	.320 (8)	.530 (14)	---	---	.25	.11	2 1/2	64
S600521	TH80000 / TW80000 / TH7000	.680 (17)	twin	3/8	twin	.45	.20	3 1/2	89
S600522	TH80000	.810 (21)	twin	1/2	twin	.49	.22	3 1/2	89
S2-HR1005	E9000	.750 (19)	1.05 (27)	1/2	13	.95	.43	3 1/2	89
S3-HR1005	E9000 / FE9000 / SD	1.06 (27)	1.38 (35)	3/4	19	.95	.43	3 1/2	89
S4-HR1005	D80000 / E9000 / FE9000 / SD	1.39 (35)	1.55 (39)	1	25	.81	.36	3 1/2	89
S600547-1	FE9500 / FF9500	1.55 (39)	1.75 (44)	1 1/4	32	.70	.31	3 3/4	95
S600547-2	FE9600 / FF9600	1.75 (44)	2.03 (52)	1 1/2	38	.57	.25	3 3/4	95