


3520CW®

FOIL INSULATION TAPE

Venture Tape 3520CW® COLD WEATHER FOIL is a 2.0-mil (50µm) annealed aluminum foil coated with Venture's CW® cold weather solvent acrylic pressure sensitive adhesive. The malleable foil applies easily to both fibrous and sheet metal ducts and conforms to irregular surfaces. Venture Tape 3520CW excels in demanding temperature and humidity applications and provides superior performance and durability over a wide range of environmental conditions.

Product Construction

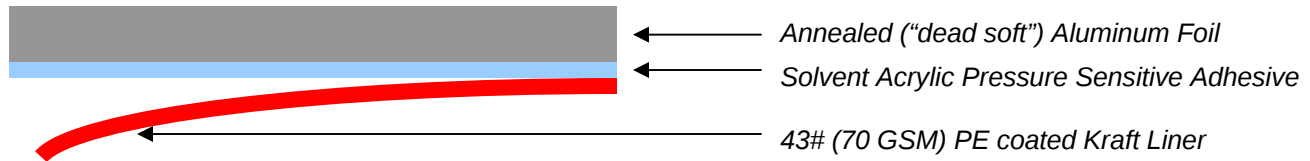

Features & Benefits

- UL723 Listed
- Specifically designed for cold weather conditions
- Specifically designed for sealing sheet metal ducts and metal duct connections
- Venture CW® cold weather solvent acrylic adhesive performs well over a wide temperature range
- Hand tearable allows for easy installation
- Also excels in high heat and humidity conditions
- In stock product available for immediate delivery

Test	Typical Value	Typical Value (Metric)	Test Method
Product Thickness (Total)	7.3 mils	185.4 µm	PSTC-133
Thickness (Carrier)	2.0 mils	50.8 µm	PSTC-133
Thickness (Adhesive)	1.7 mils	43.2 µm	PSTC-133
Thickness (Liner)	3.6 mils	91.4 µm	PSTC-133
Peel Adhesion	100 oz/in	27.8 N/25mm	PSTC-101
Shear Strength	>168 hours	>168 hours	PSTC-107
Tensile Strength	34 lb/in width	151 N/25mm width	PSTC-131
Elongation	5 %	5 %	PSTC-131
Minimum Application Temperature	-35 °F	-37 °C	
Maximum Continuous Temperature	260 °F	127 °C	
Maximum Intermittant Temperature	300 °F	149 °C	

Typical values are not intended to be used for specification development. Technical data is believed to be true and accurate; Venture Tape recommends that the purchaser test for fitness of use in all applications.

Product Configurations

- Standard sizes: 2 ½" x 50Y, 3" x 50Y
- Custom widths and lengths available, contact Venture Tape for specifications and requirements

Contact Venture Tape today for a complete list of products or a free sample

Toll Free North America 800-343-1076

From United Kingdom 0-800-962-957

From Australia 1-800-122-797

www.venturetape.com

www.boma.it

VentureTape®

USA

Venture Tape Corp.
30 Commerce Road
Rockland, MA 02370
781-331-5900
FAX 781-871-0065

Europe – Venture Tape

Venture Tape Europe Corp.
Units 5 – 6, Faraday Close,
Drayton Fields, Daventry,
Northamptonshire, England NN11 8RD
(0) 1327 876555
FAX (0) 1327 876444

Australasia

Venture Tape Australasia, Pty., Ltd.
11B Production Drive
Campbellfield 3061 Victoria
Australia
(03) 9357 6025
FAX (03) 9357 6045