

PSA-INOX-STAR-Eyebolt M20 with L=60 mm

Artikel-Nr: 7901252




- **Lifting points pivots 360°**
- **Fall arrest protection.** Statement for number of persons which can be secured.
- **Non removable special bolt**(this reduces the risk of improper standard bolts).
- Available as: - Standard Metric Thread (DIN EN 13) - Coarse Pitch Thread UNC (ANSI B1.1)
- According to EG Directive 89/686/EWG. Exceeds the requirements of DIN EN 795. Marking corresponds to DIN EN 365.
- Tested and certified by faculty PSA of DGUV.
- DGUV approval for attachment to steel and with blind rivet nuts.
- **Pentagonal shape for a clear determination to common lifting points (i.e. eye bolts).** Body and bolt made out of Duplex Steel 1.4462 (high resistancy in sea water and in environment with a high concentration of chlorine ions. Component is allowed to be used in outdoor applications.
- Quick and easy installation with just one bolt connection.
- Hand tightening with appropriate wrench is sufficient for a singular lift.

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

PSA-INOX-STAR-Eyebolt M20 with L=60 mm

Artikel-Nr: 7901252

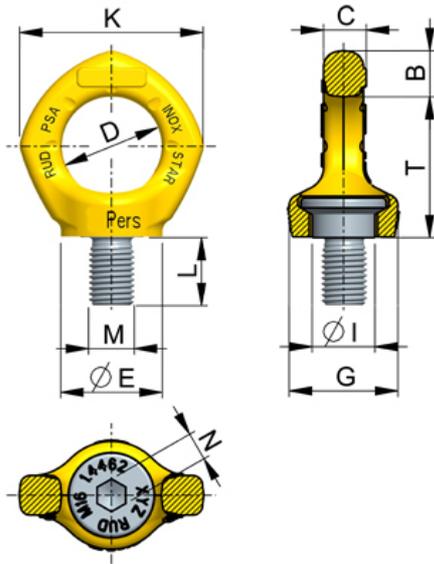

	weight	0.60 kg	1.32 lbs
T	58 mm	2-9/32"	
B	19 mm	3/4"	
C	17 mm	43/64"	
D	40 mm	1-9/16"	
E	43 mm	1-11/16"	
G	47 mm	1-7/8"	
I	27,5 mm	1-1/8"	
K	74 mm	2-29/32"	
L	60 mm	2-3/8"	
M	M20 mm	M20	
N	12 mm	15/32"	