

STARPOINT VRS-F-12t-G1-1/2" with star key

Artikel-Nr: 7901254




- Lifting points pivots 360°. Easy adjustment in load direction.
- Not exchangeable RUD-Bolt (this reduces the usage of improper standard bolts).
- Clear marking of the minimum WLL for all loading directions. Higher WLL possible when location and installation is optimised (compare WLL chart / product information).
- Clear marking at the bolt head: RUD, thread size, batch-no.
- Variable bolt lengths available for tapped or through holes.
- Available as: - Standard Metric Thread (DIN EN 13) - Metric Fine Thread (DIN EN 13) - Coarse Pitch Thread UNC (ANSI B1.1) - Fine Thread 8UN (ANSI B1.1) - Inch Pipe Thread (DIN 228)
- Significant product characteristics of the VRS are subject to property right claims.
- Component according to the test criterias of BG/DGUV "GS-HM 36".
- Complying with the US-Standard (ASME B30.26). Quick and easy installation with just one bolt connection.
- Installation and disassembly without any further tools than the exchangeable Easy-Fit star profile key for singular lifts.
- For permanent installation and recurrent lifts we can offer a special socket wrench to apply the requested torque (fits to a common Inch torque wrench).

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

STARPOINT VRS-F-12t-G1-1/2" with star key

Artikel-Nr: 7901254

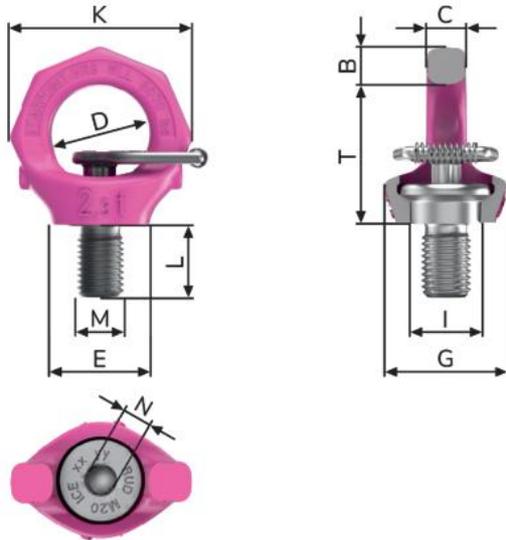

| | | |
|--------------------|-------------|-----------|
| weight | 8.18 kg | 18.03 lbs |
| Nominal WLL | 12000 kg | 26450 lbs |
| T | 138 mm | 5-7/16" |
| B | 42 mm | 1-21/32" |
| C | 38 mm | 1-1/2" |
| D | 96 mm | 3-25/32" |
| E | 101 mm | 3-31/32" |
| G | 128 mm | 5" |
| K | 179 mm | 7-1/32" |
| L | 72 mm | 2-27/32" |
| M | G 1-1/2" mm | G 1-1/2" |
| N | 27 mm | 1-1/16" |