

L-ABA 20000 daN - Lashing point for welding, loadable from any direction

Artikel-Nr: 7901723




- Lashing point that can be loaded on all sides.
- Ideal for pile drivers, drilling equipment, rollers and earthmoving machinery.
- Clear indication of the minimum lashing capacity in daN.
- Forged from a single piece, no rattling noise or shaking.
- The weld arrangement (circular fillet weld) fulfils the requirements of EN 1090, i.e. the endless weld seam prevents the formation of contact/crevice corrosion (thus suitable for outdoor constructions).

Welding should only be carried out by qualified persons according to ISO 9606-1. Other important RUD specific information and specialities to our RUD lashing points can be found in the specific user instruction.

L-ABA 20000 daN - Lashing point for welding, loadable from any direction

Artikel-Nr: 7901723

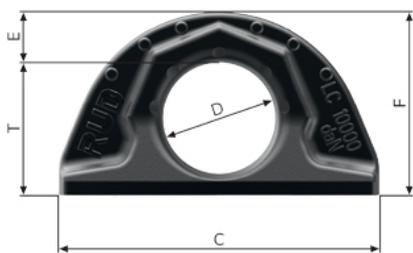

weight	5.37 kg	11.84 lbs
T	95 mm	3-3/4"
A	70 mm	2-3/4"
B	38 mm	1-1/2"
C	228 mm	9"
D	80 mm	3-1/8"
E	35 mm	1-3/8"
F	130 mm	5-1/8"
Lashing capacity	20000 daN	null