

Eye Plate for Corners VRBK-FIX 10t

Artikel-Nr: 7902256




An enhancement of the well-established VRBK - series.

- A forged ring bracket according to EN1677-1, electromagnetically crack detected, pink powder coated and it can be loaded in all directions.
- No time-consuming alignment between the weld-on blocks and ring.
- Clamp spring is protected placed inside the weld-on block.
- The spring fixes the weld-on blocks to the ring and creates at the same time a radial clamping.
- No loose items.
- Clamping spring avoids rattling noise.
- Recognition of inclination angle indicated by markings on the ring and on the blocks in all levels.
- Even force distribution owing to the two point attachment.
- Low profile size it can be folded with in an angle range of 270°.
- The welding block for edges is forged out of a good welding material 1.0577+N (St 52-3) and clearly stamped with an identification number for the permissible WLL.
- Tested and certified by DGUV, Testing specifications: GS-HM-36: 2023-06, Certificate-No.: HM 250039

Welding should only be carried out by qualified persons according to ISO 9606-1.

Eye Plate for Corners VRBK-FIX 10t

Artikel-Nr: 7902256

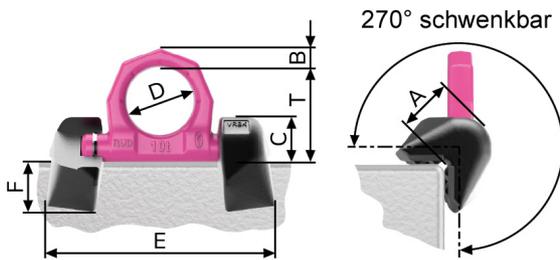

weight	4.40 kg	9.70 lbs
Nominal WLL	10000 kg	22040 lbs
T	94 mm	3-11/16"
A	52 mm	2-1/16"
B	22 mm	7/8"
C	46 mm	1-13/16"
D	65 mm	2-9/16"
E	212 mm	8-11/32"
F	46 mm	1-13/16"