

## Lashing point for corners for welding LRBK-FIX 13400 daN

Artikel-Nr: 7903057




- Lift bail with extended pivoting area, can be pivoted through 270°.
- Optimal for edges – saves half the lashing points.
- Clear indication of the lashing capacity in daN.
- Split force introduction thanks to multiple point fixing.
- LC possible up to 90° in load ring plane.
- Thanks to the weld arrangement (circular fillet weld), no contact/crevice corrosion can occur.
- The clamping spring achieves noise reduction and keeps the suspension ring in the desired direction.
- Simple alignment of ring lug.
- Ring lug remains in position.
- Simple painting.

Welding should only be carried out by qualified persons according to ISO 9606-1.

## Lashing point for corners for welding LRBK-FIX 13400 daN

Artikel-Nr: 7903057

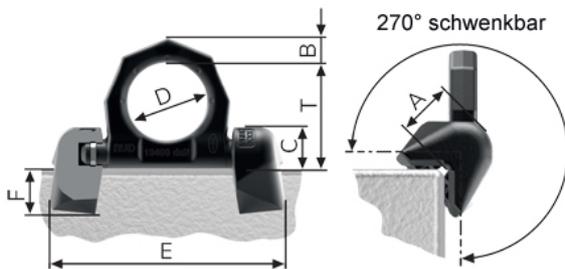

<b>weight</b>	2.16 kg	4.76 lbs
<b>T</b>	84 mm	3-5/16"
<b>A</b>	40 mm	1-9/16"
<b>B</b>	20 mm	3/4"
<b>C</b>	35 mm	1-3/8"
<b>D</b>	60 mm	2-3/8"
<b>E</b>	181 mm	7-1/8"
<b>F</b>	34 mm	1-11/32"
<b>Lashing capacity</b>	13400 daN	null