

Lashing point for corners for welding LRBK-FIX 20000 daN

Artikel-Nr: 7903058




- Lift bail with extended pivoting area, can be pivoted through 270°.
- Optimal for edges – saves half the lashing points.
- Clear indication of the lashing capacity in daN.
- Split force introduction thanks to multiple point fixing.
- LC possible up to 90° in load ring plane.
- Thanks to the weld arrangement (circular fillet weld), no contact/crevice corrosion can occur.
- The clamping spring achieves noise reduction and keeps the suspension ring in the desired direction.
- Simple alignment of ring lug.
- Ring lug remains in position.
- Simple painting.

Welding should only be carried out by qualified persons according to ISO 9606-1.

Lashing point for corners for welding LRBK-FIX 20000 daN

Artikel-Nr: 7903058

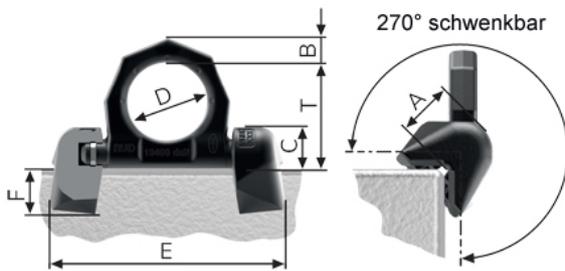

weight	4.40 kg	9.70 lbs
T	94 mm	3-11/16"
A	52 mm	2-1/16"
B	22 mm	7/8"
C	46 mm	1-13/16"
D	65 mm	2-9/16"
E	212 mm	8-11/32"
F	46 mm	1-13/16"
Lashing capacity	20000 daN	null