

VWBG-KA-28; 31,5T M72


Artikel-Nr: 7903437



Lifting point with a ball bearing for the direct connection of the VIP chain. Version VWBG-KA. Not suitable for permanent swiveling under full load. Maximum WLL with the smallest thread diameter. Choose the attachment points in such a way that the introduced forces are accommodated by the work piece without being deformed. Work piece material, at least 1.0037 (St 37). For light metals, nonferrous heavy metals and grey cast iron, the thread type allocation must be done in such a way that, the WLL of the thread type fulfils the requirements of the respective work piece. Make sure the bolting surface is plain. Ensure an appropriate bore depth to facilitate an optimal sitting of the engaging surface.

VWBG-KA-28; 31,5T M72

Artikel-Nr: 7903437

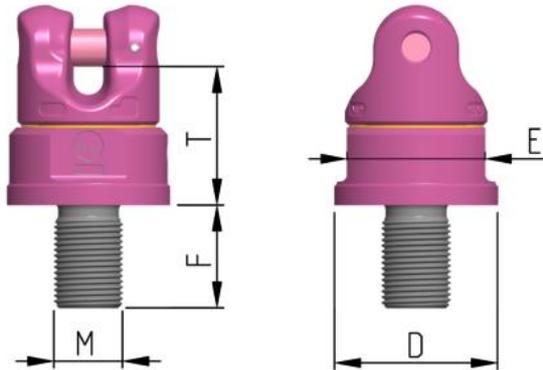

weight	26.40 kg	58.20 lbs
Nominal WLL	31500 kg	69440 lbs
T	146 mm	5-3/4"
D	170 mm	6-11/16"
F	108 mm	4-1/4"
K	145 mm	5-11/16"
M	M72 mm	M72