

## Lashing point L-VLBG-PLUS 16.000 daN M36

Artikel-Nr: 7904778




The VLBG-PLUS as a boltable heavy duty lashing point for load beds and cargo.

- Clear marking of the lashing capacity for all loading directions. LC marking with daN.
- Lashing point pivots 360°. Suspension ring pivots 180°.
- Full load in all directions
- Original-RUD bolt with special corrosion protection Corrud-DT is included in delivery as well as available as a spare part. Clear marking at the bolt head: RUD, thread size, batch-no., class of strength.
- Captive but exchangeable special bolt (this reduces the usage of improper standard bolts).
- Clamping spring works as a noise reduction and holds the suspension ring in the requested position; therefore simple hinge of lashing mean possible.
- Variable bolt lengths available for tapped or through holes.
- Quick and easy installation with just one bolt connection.
- Assembly with flat / ring wrench or allen key possible.

Other important RUD specific information and specialities to our RUD lashing points can be found in the specific user instruction.

## Lashing point L-VLBG-PLUS 16.000 daN M36

Artikel-Nr: 7904778

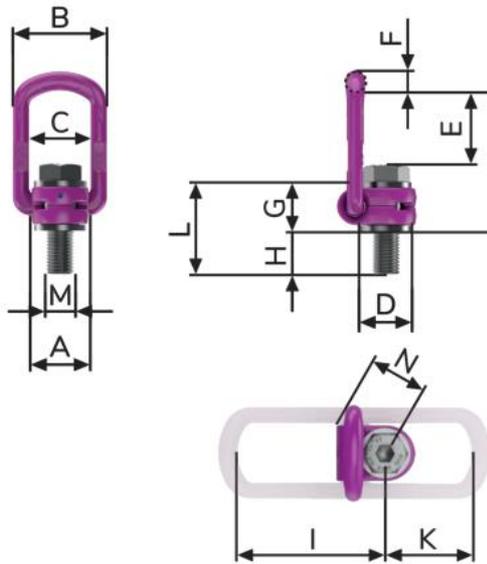

<b>weight</b>	6.00 kg	13.23 lbs
<b>T</b>	197 mm	7-3/4"
<b>A</b>	77 mm	3"-1/32"
<b>B</b>	122 mm	4-13/16"
<b>C</b>	82 mm	3-1/4"
<b>D</b>	70 mm	2-3/4"
<b>E</b>	97 mm	3-13/16"
<b>F</b>	26,5 mm	1-3/64"
<b>G</b>	77 mm	3"-1/32"
<b>H</b>	63 mm	2-15/32"
<b>I</b>	205 mm	8-1/16"
<b>K</b>	110 mm	4-11/32"
<b>L</b>	140 mm	5-1/2"
<b>M</b>	M36 mm	M36
<b>N</b>	87 mm	3-7/16"
<b>Lashing capacity</b>	16000 daN	null