

## Lifting point B-ABA 1,6t - M10

Artikel-Nr: 7906266




### B-ABA - Sturdy and resilient

- No rattling noise or shaking even at strong vibrations or shock loads, simple hinge of lifting means possible.
- Tested and certified by DGUV Testing specifications: GS-HM-36:2021-09 Certificate No.: HM 220054
- Clear marking of the minimum WLL for all loading directions.
- Clear marking at the bolt head: RUD, thread size, batch-no., class of strength.
- Original RUD bolt with special corrosion protection Corrud-DT available as spare part.
- Available as: Standard Metric Thread (DIN EN 13)
- Patented markings for easy determination for withdraw of service.
- Pink powder coated surface.
- Significant product characteristics of the B-ABA are subject to property right claims.

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

## Lifting point B-ABA 1,6t - M10

Artikel-Nr: 7906266

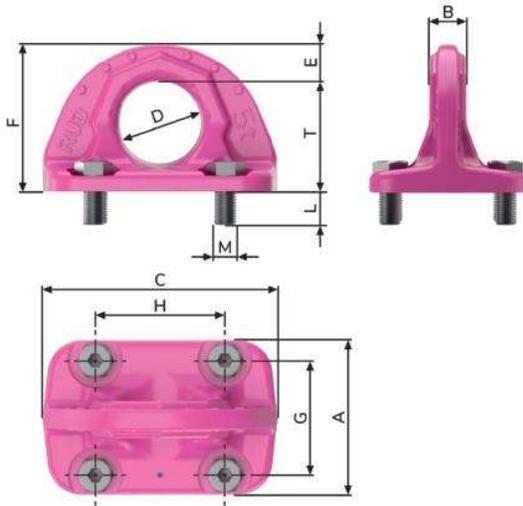

<b>weight</b>	0.88 kg	1.94 lbs
<b>Nominal WLL</b>	1600 kg	3520 lbs
<b>T</b>	47 mm	1-7/8"
<b>A</b>	75 mm	2-15/16"
<b>B</b>	16 mm	5/8"
<b>C</b>	100 mm	3-15/16"
<b>D</b>	35 mm	1-3/8"
<b>E</b>	16 mm	5/8"
<b>F</b>	62,5 mm	null
<b>G</b>	55 mm	2-5/32"
<b>H</b>	55 mm	2-5/32"
<b>L</b>	13 mm	1/2"
<b>M</b>	M10 mm	M10