

Lifting point B-ABA 3,2t - M12

Artikel-Nr: 7906267




B-ABA - Sturdy and resilient

- No rattling noise or shaking even at strong vibrations or shock loads, simple hinge of lifting means possible.
- Tested and certified by DGUV Testing specifications: GS-HM-36:2021-09 Certificate No.: HM 220054
- Clear marking of the minimum WLL for all loading directions.
- Clear marking at the bolt head: RUD, thread size, batch-no., class of strength.
- Original RUD bolt with special corrosion protection Corrud-DT available as spare part.
- Available as: Standard Metric Thread (DIN EN 13)
- Patented markings for easy determination for withdraw of service.
- Pink powder coated surface.
- Significant product characteristics of the B-ABA are subject to property right claims.

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

Lifting point B-ABA 3,2t - M12

Artikel-Nr: 7906267

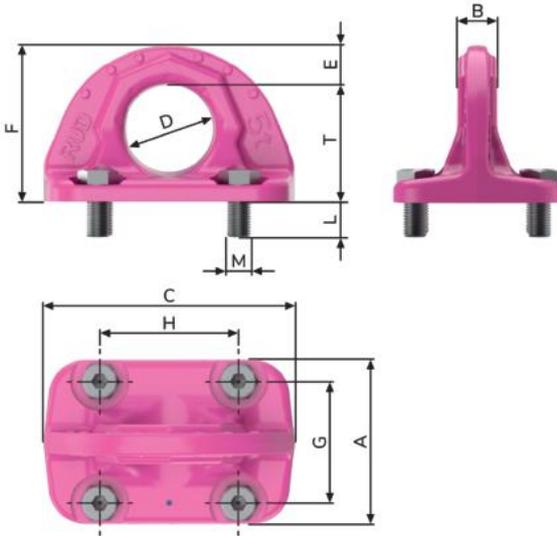

weight	2.01 kg	4.43 lbs
Nominal WLL	3200 kg	7050 lbs
T	65 mm	2-9/16"
A	92 mm	3-5/8"
B	23 mm	29/32"
C	137 mm	5-3/8"
D	50 mm	1-31/32"
E	21 mm	13/16"
F	86 mm	3-3/8"
G	70 mm	2-3/4"
H	75 mm	2-15/16"
L	16 mm	5/8"
M	M12 mm	M12