

Lifting point B-ABA 5t - M16

Artikel-Nr: 7906268




B-ABA - Sturdy and resilient

- No rattling noise or shaking even at strong vibrations or shock loads, simple hinge of lifting means possible.
- Tested and certified by DGUV Testing specifications: GS-HM-36:2021-09 Certificate No.: HM 220054
- Clear marking of the minimum WLL for all loading directions.
- Clear marking at the bolt head: RUD, thread size, batch-no., class of strength.
- Original RUD bolt with special corrosion protection Corrud-DT available as spare part.
- Available as: Standard Metric Thread (DIN EN 13)
- Patented markings for easy determination for withdraw of service.
- Pink powder coated surface.
- Significant product characteristics of the B-ABA are subject to property right claims.

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

Lifting point B-ABA 5t - M16

Artikel-Nr: 7906268

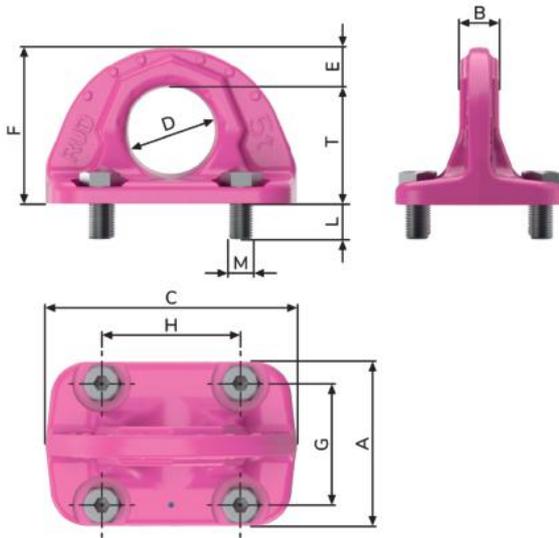

T	80 mm	3-1/8"
A	113 mm	4-7/16"
B	27 mm	1-1/16"
C	172 mm	6-25/32"
D	60 mm	2-3/8"
E	28 mm	1-1/8"
F	108 mm	4-1/4"
G	84 mm	3-5/16"
H	95 mm	3-3/4"
L	24 mm	15/16"
M	M16 mm	M16
weight	4.07 kg	8.97 lbs
Nominal WLL	5000 kg	11000 lbs