

Lifting point B-ABA 10t - M20

Artikel-Nr: 7906269




B-ABA - Sturdy and resilient

- No rattling noise or shaking even at strong vibrations or shock loads, simple hinge of lifting means possible.
- Tested and certified by DGUV Testing specifications: GS-HM-36:2021-09 Certificate No.: HM 220054
- Clear marking of the minimum WLL for all loading directions.
- Clear marking at the bolt head: RUD, thread size, batch-no., class of strength.
- Original RUD bolt with special corrosion protection Corrud-DT available as spare part.
- Available as: Standard Metric Thread (DIN EN 13)
- Patented markings for easy determination for withdraw of service.
- Pink powder coated surface.
- Significant product characteristics of the B-ABA are subject to property right claims.

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

Lifting point B-ABA 10t - M20

Artikel-Nr: 7906269

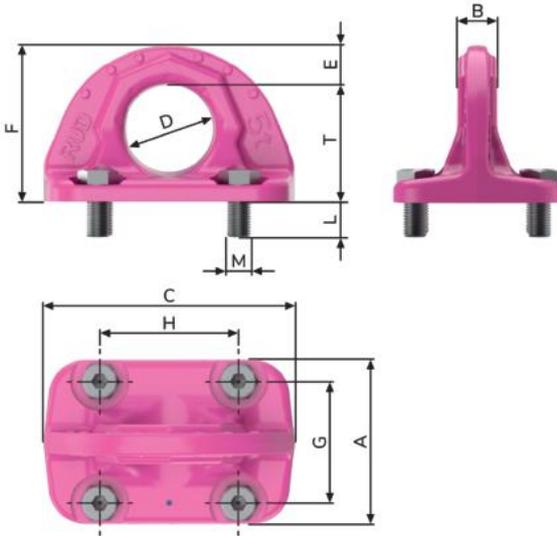

weight	9.31 kg	20.53 lbs
Nominal WLL	10000 kg	22040 lbs
T	105 mm	4-1/8"
A	146 mm	5-3/4"
B	38 mm	1-1/2"
C	228 mm	9"
D	80 mm	3-1/8"
E	36 mm	1-27/64"
F	141 mm	5-9/16"
G	110 mm	4-11/32"
H	125 mm	4-15/16"
L	25 mm	63/64"
M	M20 mm	M20