


Lifting point B-ABA 20t - M24

Artikel-Nr: 7906270

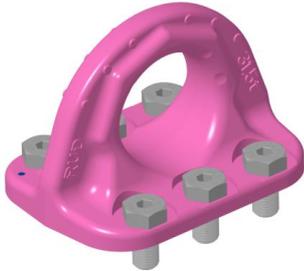


B-ABA - Sturdy and resilient

- No rattling noise or shaking even at strong vibrations or shock loads, simple hinge of lifting means possible.
- Tested and certified by DGUV Testing specifications: GS-HM-36:2021-09 Certificate No.: HM 220054
- Clear marking of the minimum WLL for all loading directions.
- Clear marking at the bolt head: RUD, thread size, batch-no., class of strength.
- Original RUD bolt with special corrosion protection Corrud-DT available as spare part.
- Available as: Standard Metric Thread (DIN EN 13)
- Patented markings for easy determination for withdraw of service.
- Pink powder coated surface.
- Significant product characteristics of the B-ABA are subject to property right claims.

Other important RUD specific information and specialities to our RUD lifting points can be found in the specific user instruction.

Lifting point B-ABA 20t - M24

Artikel-Nr: 7906270

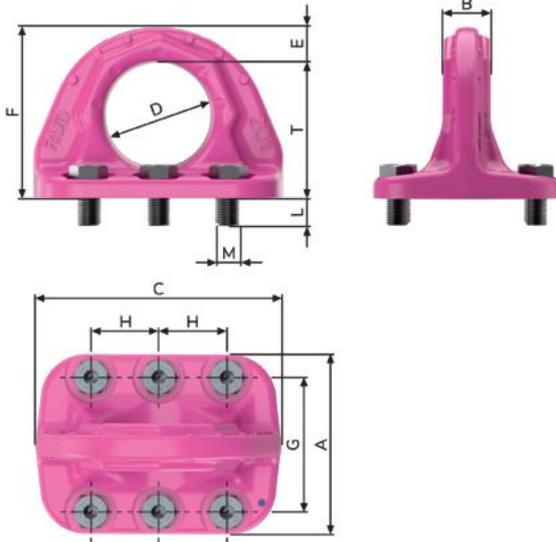

weight	18.77 kg	41.38 lbs
Nominal WLL	20000 kg	44090 lbs
T	148 mm	5-13/16"
A	200 mm	7-7/8"
B	52 mm	2-1/16"
C	272 mm	10-11/16"
D	115 mm	4-1/2"
E	40 mm	1-9/16"
F	188 mm	7-13/32"
G	150 mm	5-7/8"
H	75 mm	2-15/16"
L	30 mm	1-3/16"
M	M24 mm	M24